


Non-insulated spade terminal



SPECIFICATION:

Material	Copper
Surface material	Tin-plated

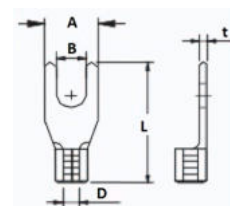

Article Nr.	AWG	Contact	D	L	A	B	t	Stud Size
RND 465-00599	22-16 AWG	0.5...1.5 mm ²	1.9 mm	16 mm	7.2 mm	4.3 mm	0.75 mm	#8
RND 465-00692	16-14 AWG	1.5...2.5 mm ²	4.1 mm	16 mm	8 mm	5.3 mm	0.8 mm	#10