

Blade Connector



FEATURES:


Nylon, fully-insulated

Male disconnect

Funnel entry

SPECIFICATION:

Material	Brass
Insulation material	Nylon
Surface material	Tin-plated
Temperature range	max. +105 °C

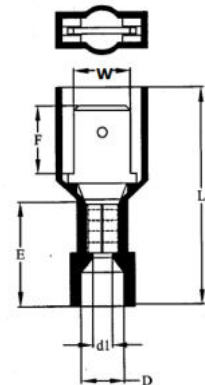

Article Nr.	Tab Size	AWG	Contact	Colour	D	L	W	d1	E	F
RND 465-00695	6.3 x 0.8 mm	22-16 AWG	0.5...1.5 mm ²	Red	3.9 mm	25 mm	6.4 mm	1.7 mm	12.5 mm	8.1 mm
RND 465-00696	6.3 x 0.8 mm	16-14 AWG	1.5...2.5 mm ²	Blue	4.4 mm	25 mm	6.4 mm	2.3 mm	12.5 mm	8.1 mm
RND 465-00697	6.3 x 0.8 mm	12-10 AWG	4...6 mm ²	Yellow	6.7 mm	28.8 mm	6.4 mm	3.4 mm	14.5 mm	8.1 mm