


# Mains Cable

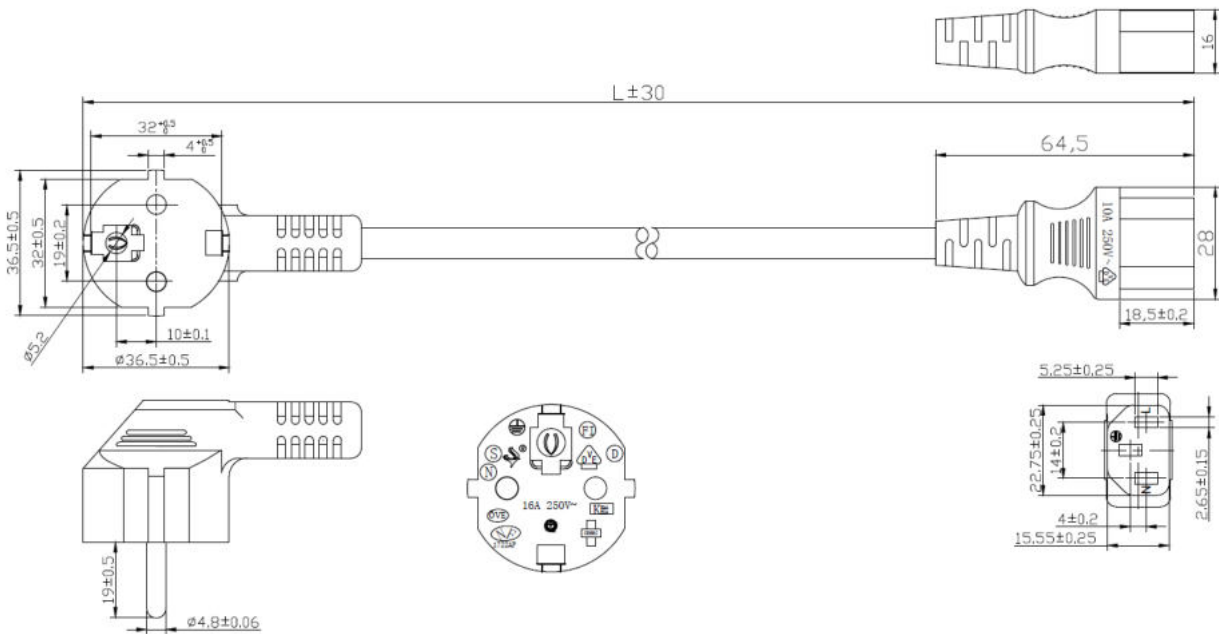

## Specification

Connector A	Type F (CEE 7/4)
Connector B	IEC 60320 C13
Connector Orientation	Straight/Angled
Cross-Section	1 mm <sup>2</sup>
Current Rating	16 A
Jacket Colour	Black
Jacket Material	PVC
Length (L)	5 m
Voltage Rating Max.	250 V

### Notes:

- 1.Cable: H05VV-F 3G1.0<sup>2</sup>mm Jacket Ø7.0±0.1 Conductor 32\*0.198
- 2.Mark: <VDE> H05VV-F 3G1.0mm<sup>2</sup>
- 3.Test:Hi-pot: Inner Voltage AC2500V/1S , External Voltage AC4500V/1S  
current leakage 1mA, insulation resistance no less than 50M Ω, no strike out;

**Art. Nr.**  
**RND 465-00933**

## Product Range

Product name	Model specification	Remarks
RND 465-00929	H05VV-F 3G 0.75mm <sup>2</sup> 0.5M	Black
RND 465-00930	H05VV-F 3G 0.75mm <sup>2</sup> 1.8M	Black
RND 465-00931	H05VV-F 3G 0.75mm <sup>2</sup> 2.0M	Black
RND 465-00932	H05VV-F 3G 1.5mm <sup>2</sup> 3.0M	Black
RND 465-00933	H05VV-F 3G 1.0mm <sup>2</sup> 5.0M	Black
RND 465-00934	H05VV-F 3G 1.5mm <sup>2</sup> 10M	Black
RND 465-00935	H05VV-F 3G 0.75mm <sup>2</sup> 1.8M	White
RND 465-00936	H05VV-F 3G 0.75mm <sup>2</sup> 2.0M	White