


Mains Cable

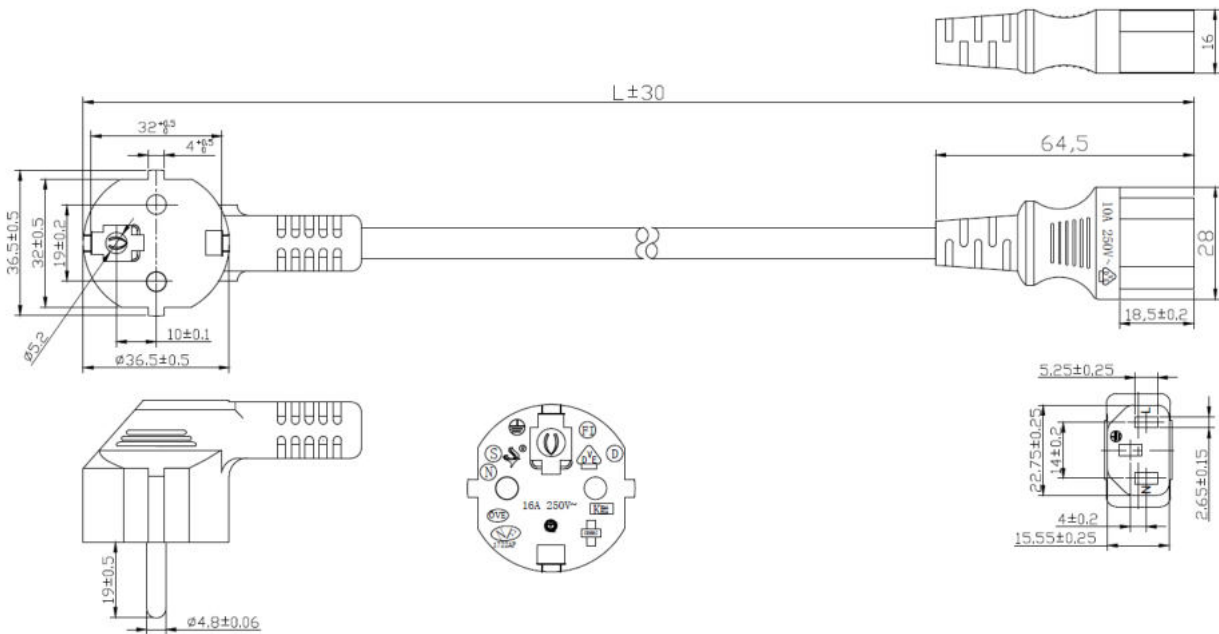

Specification

Connector A	Type F (CEE 7/4)
Connector B	IEC 60320 C13
Connector Orientation	Straight/Angled
Cross-Section	1.5 mm ²
Current Rating	16 A
Jacket Colour	Black
Jacket Material	PVC
Length (L)	10 m
Voltage Rating Max.	250 V

Notes:

- 1.Cable:H05VV-F 3G1.5²mm Jacket $\varnothing 7.9 \pm 0.1$ Conductor 48*0.198
- 2.Mark: \triangleleft VDE \triangleright H05VV-F 3G1.5mm²
- 3.Test:Hi-pot: Inner Voltage AC2500V/1S , External Voltage AC4500V/1S
current leakage 1mA, insulation resistance no less than 50M Ω , no strike out;

Art. Nr.
RND 465-00934

Product Range

Product name	Model specification	Remarks
RND 465-00929	H05VV-F 3G 0.75mm ² 0.5M	Black
RND 465-00930	H05VV-F 3G 0.75mm ² 1.8M	Black
RND 465-00931	H05VV-F 3G 0.75mm ² 2.0M	Black
RND 465-00932	H05VV-F 3G 1.5mm ² 3.0M	Black
RND 465-00933	H05VV-F 3G 1.0mm ² 5.0M	Black
RND 465-00934	H05VV-F 3G 1.5mm ² 10M	Black
RND 465-00935	H05VV-F 3G 0.75mm ² 1.8M	White
RND 465-00936	H05VV-F 3G 0.75mm ² 2.0M	White