


Mains Cable

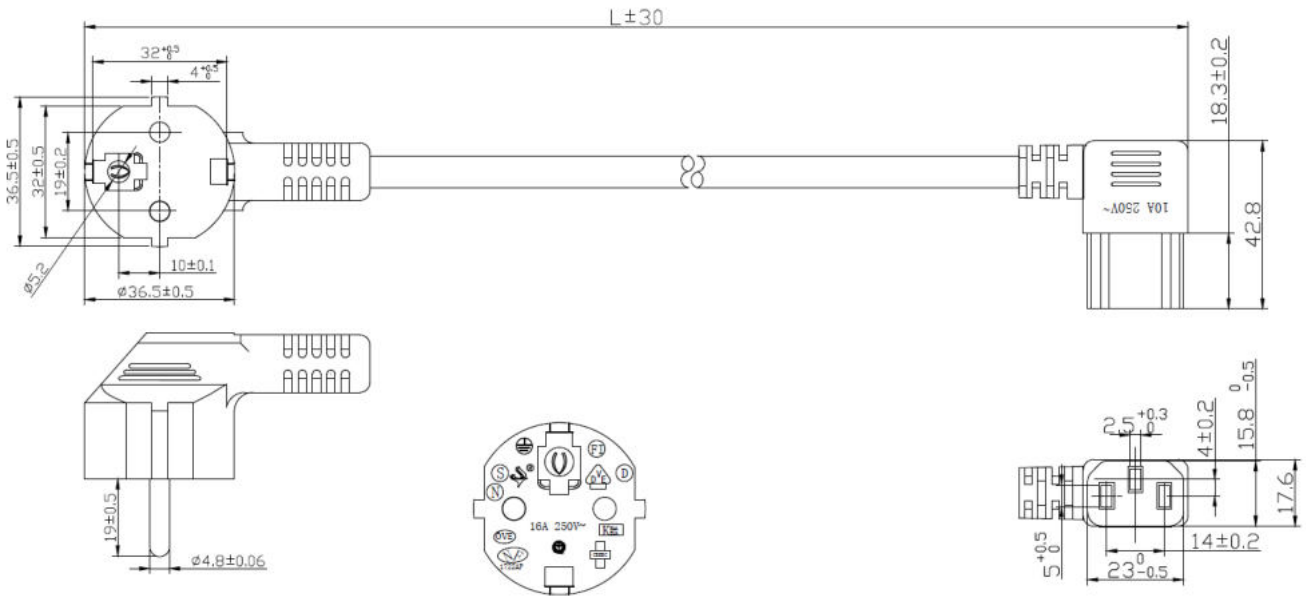

Specification

| | |
|-----------------------|-------------------|
| Connector A | Type F (CEE 7/4) |
| Connector B | IEC 60320 C13 |
| Connector Orientation | Angled |
| Cross-Section | 1 mm ² |
| Current Rating | 16 A |
| Jacket Colour | Black |
| Jacket Material | PVC |
| Length (L) | 5 m |
| Voltage Rating Max. | 250 V |

Notes:

- 1.Cable: H05VV-F 3G1.0²mm Jacket $\varnothing 7.0 \pm 0.1$ Conductor 32*0.198
- 2.Mark: \triangleleft VDE \triangleright H05VV-F 3G1.0mm²
- 3.Test:Hi-pot: Inner Voltage AC2500V/1S , External Voltage AC4500V/1S
current leakage 1mA, insulation resistance no less than 50M Ω , no strike out;

Art. Nr.
RND 465-00938

Product Range

| Product name | Model specification | Remarks |
|---------------|-------------------------------------|---------|
| RND 465-00937 | H05VV-F 3G 1.0mm ² 2.5M | Black |
| RND 465-00938 | H05VV-F 3G 1.0mm ² 5.0M | Black |
| RND 465-00939 | H05VV-F 3G 0.75mm ² 0.5M | White |
| RND 465-00940 | H05VV-F 3G 0.75mm ² 2.0M | White |