


Mains Cable

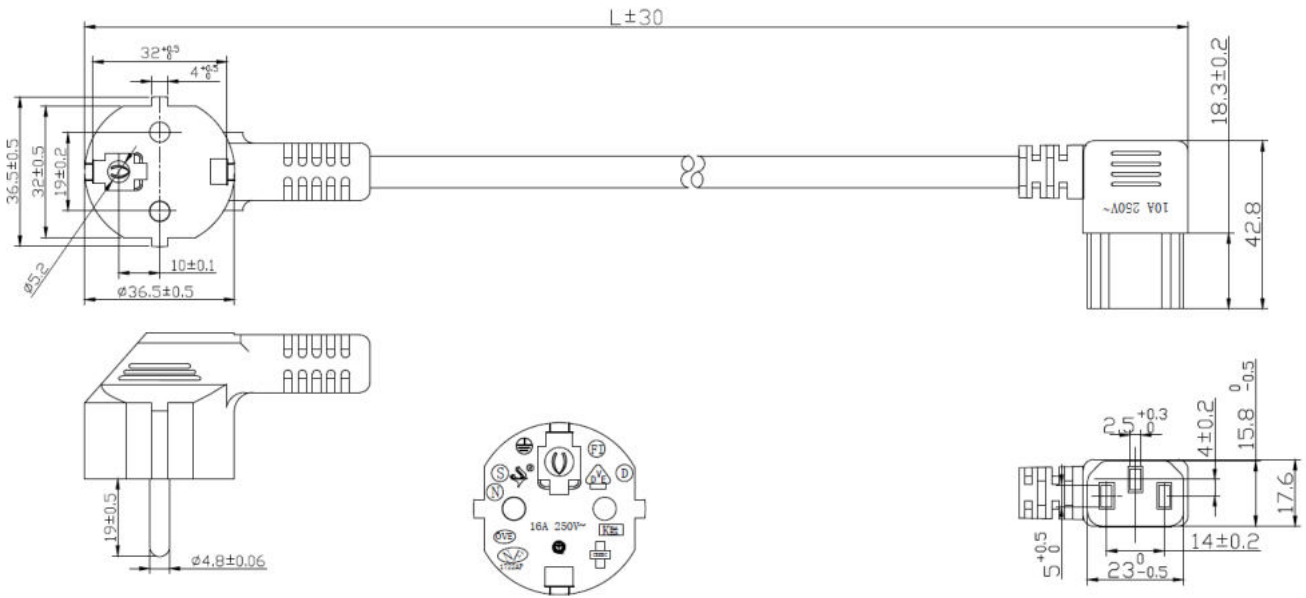

Specification

Connector A	Type F (CEE 7/4)
Connector B	IEC 60320 C13
Connector Orientation	Angled
Cross-Section	0.75 mm ²
Current Rating	16 A
Jacket Colour	White
Jacket Material	PVC
Length (L)	500 mm
Voltage Rating Max.	250 V

Notes:

- 1.Cable:H05VV-F 3G0.75²mm Jacket Ø6.5±0.1 Conductor 24*0.198
- 2.Mark: <VDE> H05VV-F 3G0.75mm²
- 3.Test:Hi-pot: Inner Voltage AC2500V/1S , External Voltage AC4500V/1S
current leakage 1mA, insulation resistance no less than 50M Ω, no strike out;

Art. Nr.
RND 465-00939

Product Range

Product name	Model specification	Remarks
RND 465-00937	H05VV-F 3G 1.0mm ² 2.5M	Black
RND 465-00938	H05VV-F 3G 1.0mm ² 5.0M	Black
RND 465-00939	H05VV-F 3G 0.75mm ² 0.5M	White
RND 465-00940	H05VV-F 3G 0.75mm ² 2.0M	White