


Mains Cable

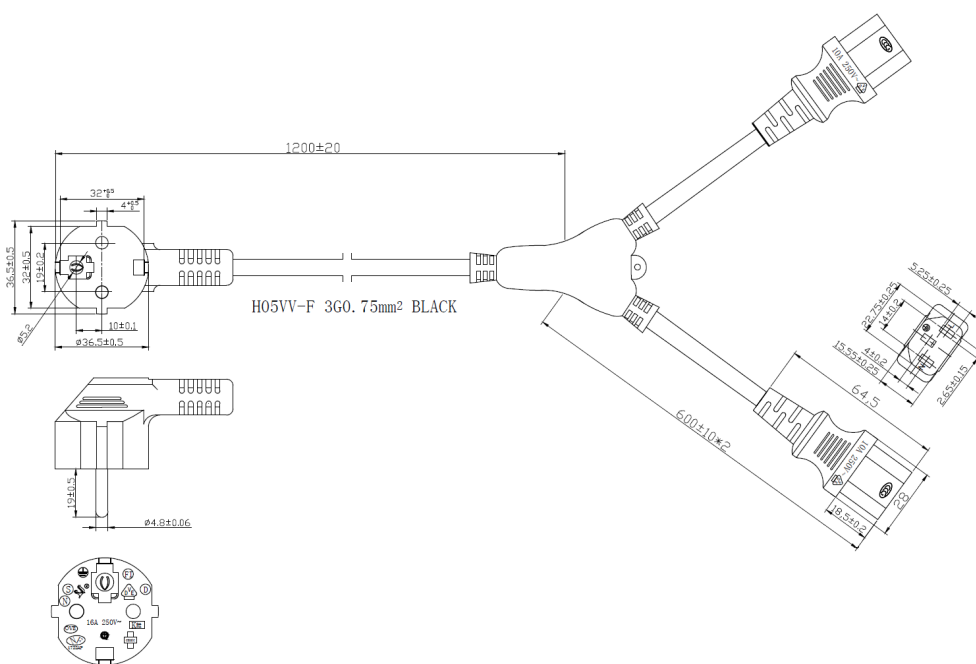

Specification

Connector A	Type F (CEE 7/4)
Connector B	2x IEC 60320 C13
Connector Orientation	Straight/Angled
Cross-Section	0.75 mm ²
Current Rating	16 A
Jacket Colour	Black
Jacket Material	PVC
Length (L)	1.8 m
Voltage Rating Max.	250 V

Notes:

- 1.Cable:H05VV-F 3G0.75²mm Jacket $\phi 6.5 \pm 0.1$ Conductor 24*0.198
- 2.Mark: \triangleleft VDE \triangleright H05VV-F 3G0.75mm²
- 3.Test:Hi-pot: Inner Voltage AC2500V/1S , External Voltage AC4500V/1S
current leakage 1mA, insulation resistance no less than 50M Ω , no strike out;

Art. Nr.
RND 465-00941