


Mains Cable

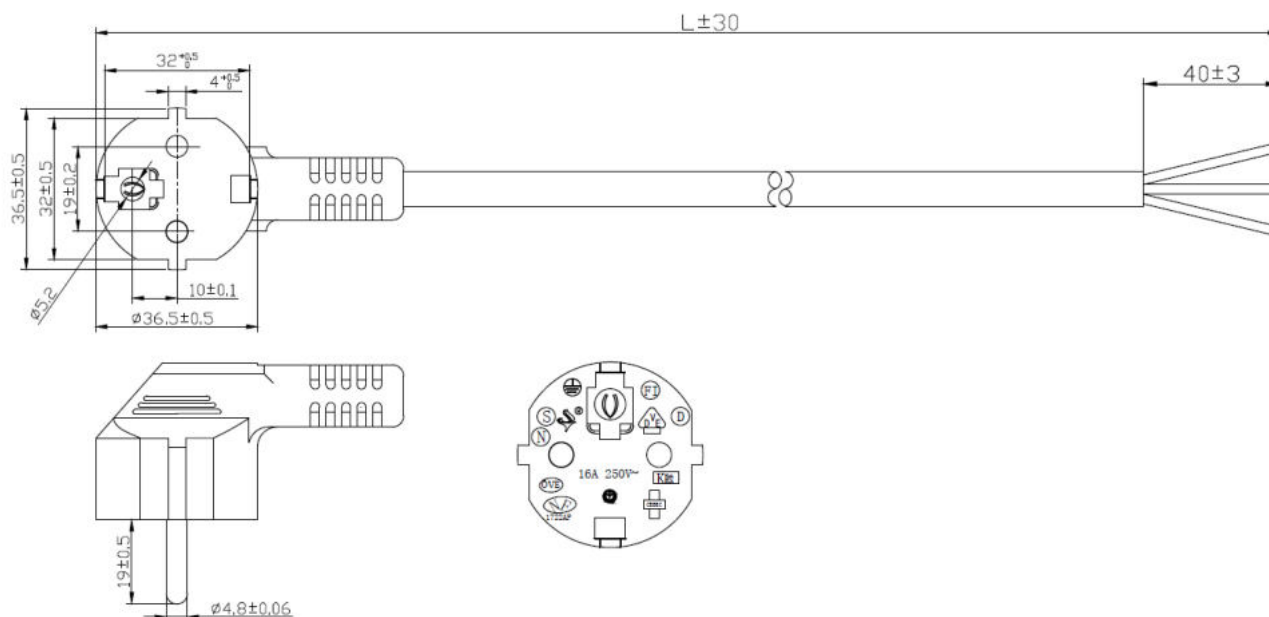

Specification

Connector A	Type F (CEE 7/4)
Connector B	Open End Connector
Connector Orientation	Straight/Angled
Cross-Section	1.5 mm ²
Current Rating	16 A
Jacket Colour	Black
Jacket Material	PVC
Length (L)	2.5 m
Voltage Rating Max.	250 V

Notes:

- 1.Cable:H05VV-F 3G1.5²mm Jacket $\varnothing 7.9 \pm 0.1$ Conductor 48*0.198
- 2.Mark: \triangleleft VDE \triangleright H05VV-F 3G1.5mm²
- 3.Test:Hi-pot: Inner Voltage AC2500V/1S , External Voltage AC4500V/1S
current leakage 1mA, insulation resistance no less than 50M Ω , no strike out;

Art. Nr.
RND 465-00952

Product Range

Product name	Model specification	Remarks
RND 465-00951	H05VV-F 3G 0.75mm ² 2.0M	Black
RND 465-00952	H05VV-F 3G 1.5mm ² 2.5M	Black
RND 465-00953	H05VV-F 3G 1.0mm ² 3.0M	Black
RND 465-00954	H05VV-F 3G 1.5mm ² 4.0M	Black
RND 465-00955	H05VV-F 3G 1.0mm ² 5.0M	Black
RND 465-00956	H05VV-F 3G 0.75mm ² 2.0M	White
RND 465-00957	H05VV-F 3G 1.0mm ² 2.5M	White
RND 465-00958	H05VV-F 3G 1.0mm ² 3.0M	White
RND 465-00959	H05VV-F 3G 1.0mm ² 5.0M	White