


# Mains Cable

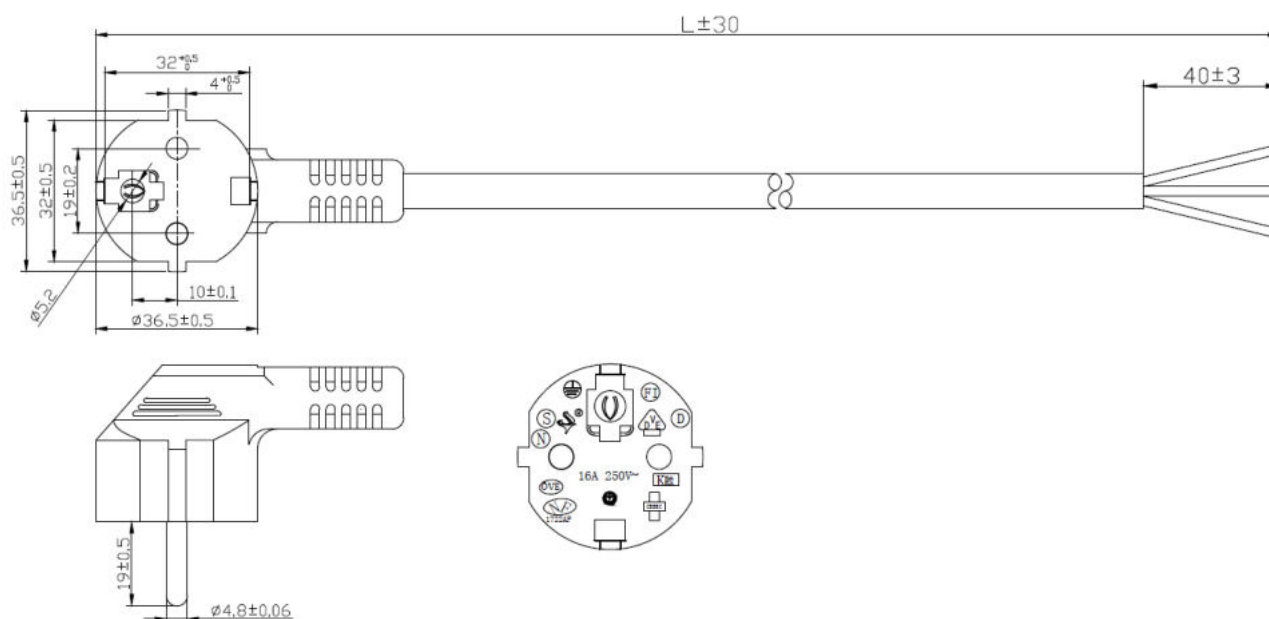

## Specification

Connector A	Type F (CEE 7/4)
Connector B	Open End Connector
Connector Orientation	Straight/Angled
Cross-Section	1.5 mm <sup>2</sup>
Current Rating	16 A
Jacket Colour	Black
Jacket Material	PVC
Length (L)	4 m
Voltage Rating Max.	250 V

### Notes:

- 1.Cable:H05VV-F 3G1.5<sup>2</sup>mm Jacket  $\phi 7.9 \pm 0.1$  Conductor 48\*0.198
- 2.Mark:  $\triangleleft$  VDE  $\triangleright$  H05VV-F 3G1.5mm<sup>2</sup>
- 3.Test:Hi-pot: Inner Voltage AC2500V/1S , External Voltage AC4500V/1S  
current leakage 1mA, insulation resistance no less than 50M  $\Omega$ , no strike out;

Art. Nr.  
RND 465-00954

## Product Range

Product name	Model specification	Remarks
RND 465-00951	H05VV-F 3G 0.75mm <sup>2</sup> 2.0M	Black
RND 465-00952	H05VV-F 3G 1.5mm <sup>2</sup> 2.5M	Black
RND 465-00953	H05VV-F 3G 1.0mm <sup>2</sup> 3.0M	Black
RND 465-00954	H05VV-F 3G 1.5mm <sup>2</sup> 4.0M	Black
RND 465-00955	H05VV-F 3G 1.0mm <sup>2</sup> 5.0M	Black
RND 465-00956	H05VV-F 3G 0.75mm <sup>2</sup> 2.0M	White
RND 465-00957	H05VV-F 3G 1.0mm <sup>2</sup> 2.5M	White
RND 465-00958	H05VV-F 3G 1.0mm <sup>2</sup> 3.0M	White
RND 465-00959	H05VV-F 3G 1.0mm <sup>2</sup> 5.0M	White