


Insulated Receptacle Disconnectors



Specification

Terminal Material	Brass
Terminal Metallic Thickness	0.40 mm
Insulation Material	PVC
Reinforced Sleeve Material	Copper
Max Temperature	75 °C
Max Voltage	300 V
Max Current	10 A
Wire Range	22-16 AWG

Drawing

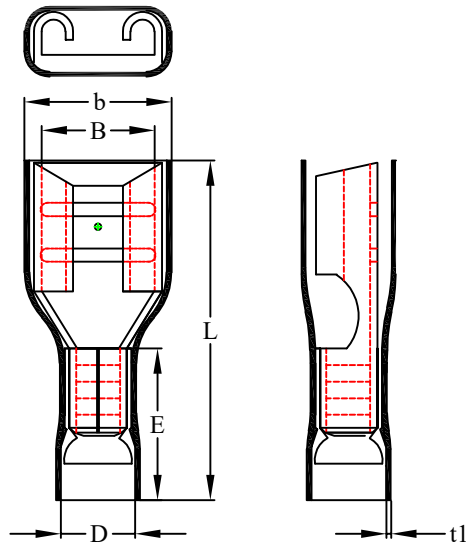

B	6.70 mm
b	9.40 mm
L	22 mm
D	4.30 mm
E	10.50 mm
t1	0.80 mm

Art. Nr.
RND 465-01359