


Insulated Receptacle Disconnect



Specification

Terminal Material	Brass
Terminal Metallic Thickness	0.40 mm
Insulation Material	PVC
Reinforced Sleeve Material	Copper
Max Temperature	75 °C
Max Voltage	300 V
Max Current	15 A
Wire Range	16-14 AWG

Drawing

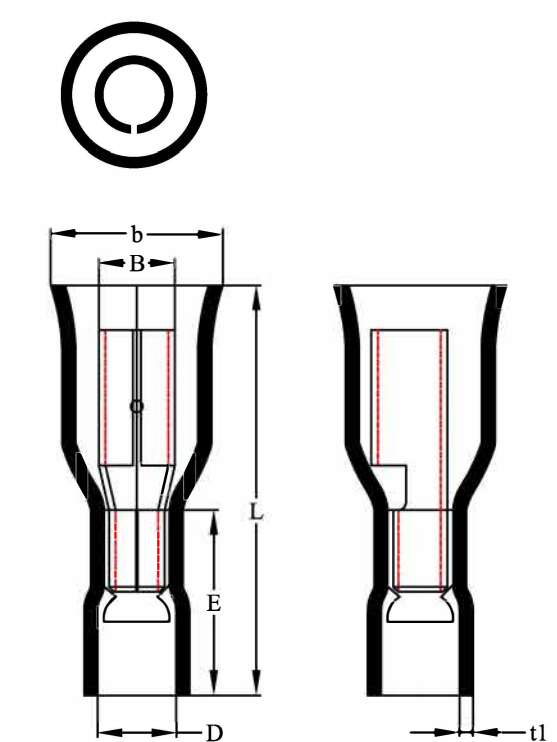

B	5.65 mm
b	7.80 mm
L	25 mm
D	4.90 mm
E	11 mm
t1	0.80 mm

Art. Nr.
RND 465-01360