


Ribbon Cable, PVC

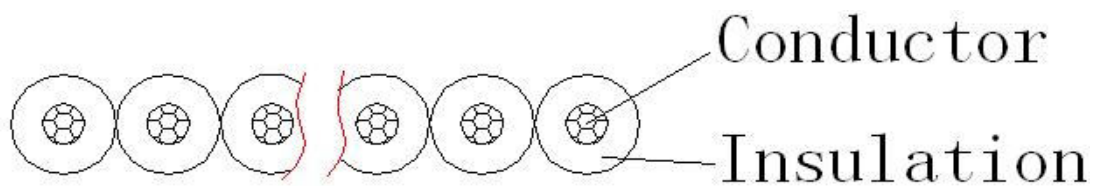

Specification

Conductor Material	Stranded bare copper
Conductor Size	28/0.15AS±0.008mm*20PCS
Min. Average Thickness	0.44mm±0.05mm
Insulation Material	45P PVC
Pitch	1.8mm
Outer Diameter	1.8mm±0.05mm*36mm±1.0mm
Temperature	80°C
Colour	Brown , Red , Orange, Yellow, Green, Blue, Purple, Grey, White, Black
Roll	30M/Roll
Operating Temperature Min.	-15 °C
Voltage rating	300 V
Fire behaviour	UL 94 V2



Art. Nr.
RND 475-00803