


Ribbon Cable, PVC

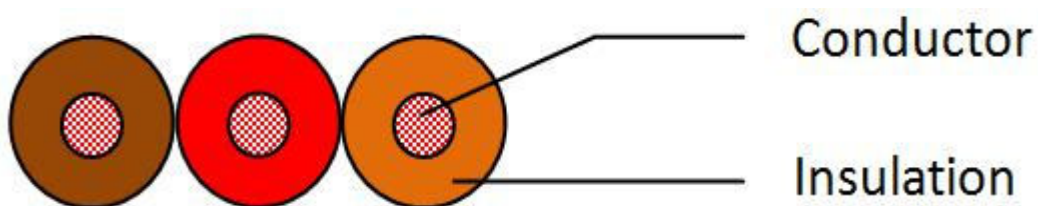

Specification

Conductor Material	Stranded bare copper
Conductor Size	14/0.15AS±0.008mm*3PCS
Min. Average Thickness	0.37mm±0.05mm
Insulation Material	45P PVC
Pitch	1.4mm
Outer Diameter	1.4mm±0.05mm*4.2mm±0.15mm
Temperature	80°C
Colour	Brown , Red , Orange
Roll	30M/Roll
Operating Temperature Min.	-15 °C
Voltage rating	300 V
Fire behaviour	UL 94 V2



Art. Nr.
RND 475-00804