


# Ribbon Cable, PVC

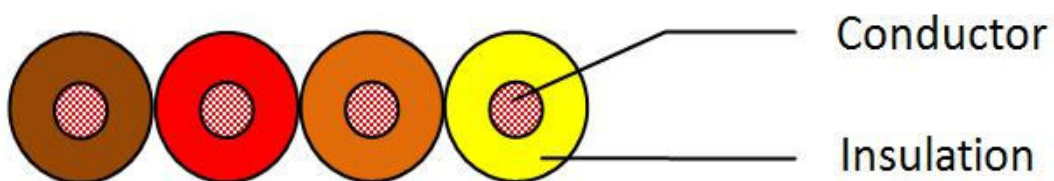

## Specification

Conductor Material	Stranded bare copper
Conductor Size	8/0.15AS±0.008mm*4PCS
Min. Average Thickness	0.3mm±0.05mm
Insulation Material	45P PVC
Pitch	1.1mm
Outer Diameter	1.1mm±0.05mm*4.4mm±0.15mm
Temperature	80°C
Colour	Brown , Red , Orange, Yellow
Roll	30M/Roll
Operating Temperature Min.	-15 °C
Voltage rating	300 V
Fire behaviour	UL 94 V2



**Art. Nr.**  
**RND 475-00805**