

Side Cutting Pliers



DESCRIPTION:

Mini side cutters for professionals with very slim, oval head, for finest operations

Pliers made from high grade special steel for extremely high requirements

By precision inductiv hardness process blades achieve up to 65 HRC

Box joint - double leaf spring

Precise jaw adjustment without backlash

High gloss steel polished surface

Ergonomically formed bicoloured hand guard - dissipative anti-slide material


The pliers have been tested with good results by several test laboratories adequate to DIN EN 61340-5-1, DIN 61340-2-1, DIN 61340-2-3 for work in ESD protected areas

SPECIFICATION:

| | |
|------------------------------|------------------|
| Length | 120 mm |
| A - Head width | 9 mm |
| C - Head thickness | 6 mm |
| G - Blade / jaw length | 9 mm |
| Cutting edge bevel | Fine - Flush cut |
| Cutting capacity soft wire | Ø 1.5 mm |
| Cutting capacity medium wire | Ø 0.8 mm |
| Cutting capacity hard wire | - |
| Weight | 55 g |

Art. Nr.

RND 550-00244

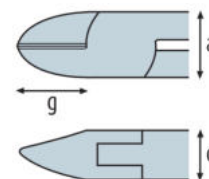

a=9mm/.354"

c=6mm/.236"

g=9mm/.354"