

# Side Cutting Pliers



## DESCRIPTION:

Side cutters for professionals with very slim, tapered head and relieved jaws

Pliers made from high grade special steel for extremely high requirements

By precision inductiv hardness process blades achieve up to 65 HRC

Box joint - double leaf spring

Precise jaw adjustment without backlash

High gloss steel polished surface

Ergonomically formed bicoloured hand guard - dissipative anti-slide material


The pliers have been tested with good results by several test laboratories adequate to DIN EN 61340-5-1, DIN 61340-2-1, DIN 61340-2-3 for work in ESD protected areas

## SPECIFICATION:

Length	125 mm
A - Head width	11 mm
C - Head thickness	7.5 mm
G - Blade / jaw length	13 mm
Cutting edge bevel	Without - Full flush cut
Cutting capacity soft wire	Ø 1.5 mm
Cutting capacity medium wire	Ø 0.8 mm
Cutting capacity hard wire	-
Weight	62 g

Art. Nr.

RND 550-00253

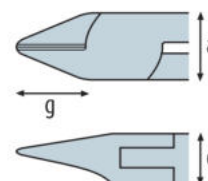

a=11mm/.433"  
c=7.5mm/.295"  
g=13mm/.512"