

Oblique Cutting Pliers



DESCRIPTION:

Oblique cutters for professionals, compact, handy, straight head for horizontal and vertical use

Special pliers made from high grade special steel for extremely high requirements

By precision inductiv hardness process blades achieve up to 65 HRC

Box joint - double leaf spring

Precise jaw adjustment without backlash

High gloss steel polished surface

Ergonomically formed bicoloured hand guard - dissipative anti-slide material


The pliers have been tested with good results by several test laboratories adequate to DIN EN 61340-5-1, DIN 61340-2-1, DIN 61340-2-3 for work in ESD protected areas

SPECIFICATION:

Length	120 mm
A - Head width	10 mm
B - Head length	10 mm
C - Head thickness	6.5 mm
G - Blade / jaw length	12 mm
Cutting edge bevel	Fine - Flush cut
Cutting capacity soft wire	Ø 1.2 mm
Cutting capacity medium wire	Ø 1 mm
Cutting capacity hard wire	Ø 0.4 mm
Weight	62 g

Art. Nr.

RND 550-00258

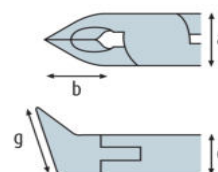

a=10mm/.394"
b=10mm/.394"
c=6.5mm/.256"
g=12mm/.473"