

Flat Nose Pliers



DESCRIPTION:

Flat nose pliers for professionals with straight, very long, smooth and strong jaws

Special pliers made from high grade special steel for extremely high requirements

For gripping, bending and holding

Box joint - double leaf spring

Precise jaw adjustment without backlash

High gloss steel polished surface

Ergonomically formed bicoloured hand guard - dissipative anti-slide material


The pliers have been tested with good results by several test laboratories adequate to DIN EN 61340-5-1, DIN 61340-2-1, DIN 61340-2-3 for work in ESD protected areas

SPECIFICATION:

Length	200 mm
A - Head width	14 mm
B - Head length	75 mm
C - Head thickness	8.5 mm
D - Jaws thickness	1.5 mm
E - Jaws width	5.5 mm
Weight	130 g

Art. Nr.

RND 550-00276

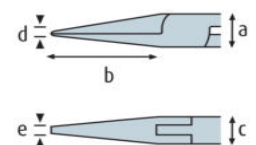

a=14mm/.550"
b=75mm/3"
c=8.5mm/.335"
d=1.5mm/.059"
e=5.5mm/.217"