

Precision Electronic Screwdriver




Specification

Battery Voltage	3.7 VDC
No-Load Speed	150 rpm
Output Torque	0.25 ... 0.35 Nm
Battery Type	Lithium Battery
Charging Time	45 min
Length	180 mm
Weight	800 g
Battery Capacity	260 mAh

Kit Contents

- 1x Precision screwdriver
- 1x Magnetic worktable
- 50x 28 mm bits, 4x 46 mm bits
- 1x USB cable
- 1x Magnetizing/demagnetizing device
- 1x Lengthening rod

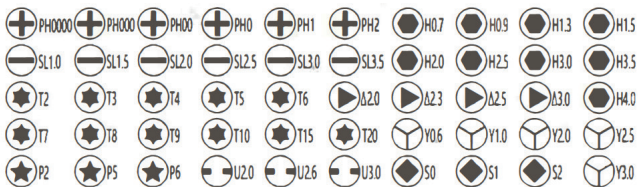

- Bits -H4X28 x 5
- Bits -H2.0, H2.5, SL2.5, PH2, PH0

= . #



Micro USB



Connect USB



Charging, white light on



Complete, blue light on

Attention

- Please stop using this product if the product accidentally falls into the water or splashes into the machine, so as not to cause a short circuit;
- Please do not dismantle the product without authorization;
- Please operate according to the instructions;
- Please try to ensure that the electric screwdriver is recharged once a month to maintain good performance.

Art. Nr.
RND 550-00379

