


Heavy-Duty Bolt Hose Clamps RND cable

Features

- RNDs heavy duty industrial hose clip clamp, gives a high level of band tensile force
- It is supplied with a high quality stainless steel screw (302Cu) which allows for the maximum tension to be applied
- The heavy duty clamp is commonly used for severe difficult applications where the seal is critical

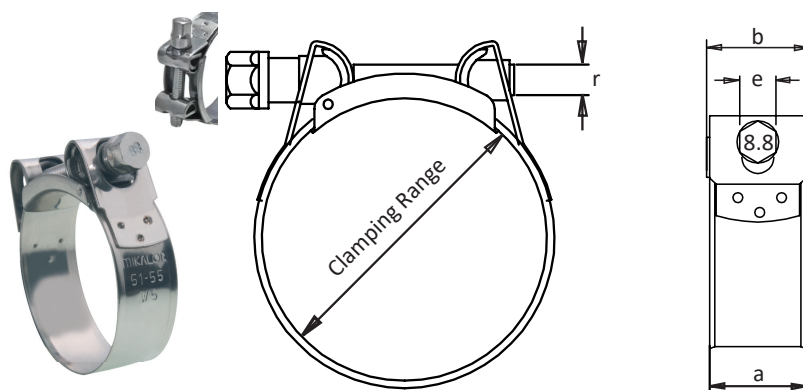

SPECIFICATION:

Material	Band and Bridge: W4, X5CrNi 1810 Stainless Steel (DIN 1.4301) (AISI-304) (A2) Bolt: AISI 302Cu Stainless Steel
Standard	Complies with DIN 3017-3

Art. Nr.	Clamping Range (mm)	r	e (mm)	a (mm)	b (mm)
RND 610-00777	17 ... 19	M6	8	18 ±0.2	19.8
RND 610-00778	19 ... 21	M6	8	18 ±0.2	19.8
RND 610-00779	21 ... 23	M6	8	18 ±0.2	19.8
RND 610-00780	23 ... 25	M6	8	18 ±0.2	19.8
RND 610-00781	25 ... 27	M6	8	18 ±0.2	19.8
RND 610-00782	27 ... 29	M6	8	18 ±0.2	19.8
RND 610-00783	29 ... 31	M7	10	20 ±0.3	22
RND 610-00784	31 ... 34	M7	10	20 ±0.3	22
RND 610-00785	34 ... 37	M7	10	20 ±0.3	22
RND 610-00786	37 ... 40	M7	10	20 ±0.3	22
RND 610-00787	40 ... 43	M7	10	20 ±0.3	22
RND 610-00788	43 ... 47	M7	10	20 ±0.3	22
RND 610-00789	47 ... 51	M7	10	20 ±0.3	22
RND 610-00790	51 ... 55	M7	10	20 ±0.3	22
RND 610-00791	55 ... 59	M7	10	20 ±0.3	22
RND 610-00792	59 ... 63	M7	10	20 ±0.3	22
RND 610-00793	63 ... 68	M7	10	20 ±0.3	22
RND 610-00794	68 ... 73	M8	13	25 ±0.4	27.5
RND 610-00795	73 ... 79	M8	13	25 ±0.4	27.5
RND 610-00796	79 ... 85	M8	13	25 ±0.4	27.5
RND 610-00797	85 ... 91	M8	13	25 ±0.4	27.5
RND 610-00798	91 ... 97	M8	13	25 ±0.4	27.5
RND 610-00799	97 ... 104	M8	13	25 ±0.4	27.5
RND 610-00800	104 ... 112	M8	13	25 ±0.4	27.5
RND 610-00801	112 ... 121	M8	13	25 ±0.4	27.5
RND 610-00802	121 ... 130	M8	13	25 ±0.4	27.5