

# USB WebCam

HD 1080P

Voice intercom



**Full HD**  
**1080P**

USB (with no drive) / Plug and play / PC and Notebook universal

# Main Function



HD 1080P




Voice intercom




Plug and play



Video

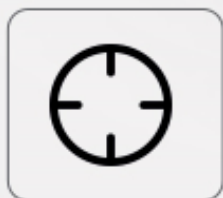

Auto focus

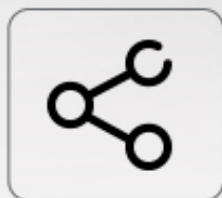


PC/Notebook

# Rotatable base

## Easy to place

### Shaft connection

Unique process design. easy to adapt to various models ingenuity, tailor-made for you.

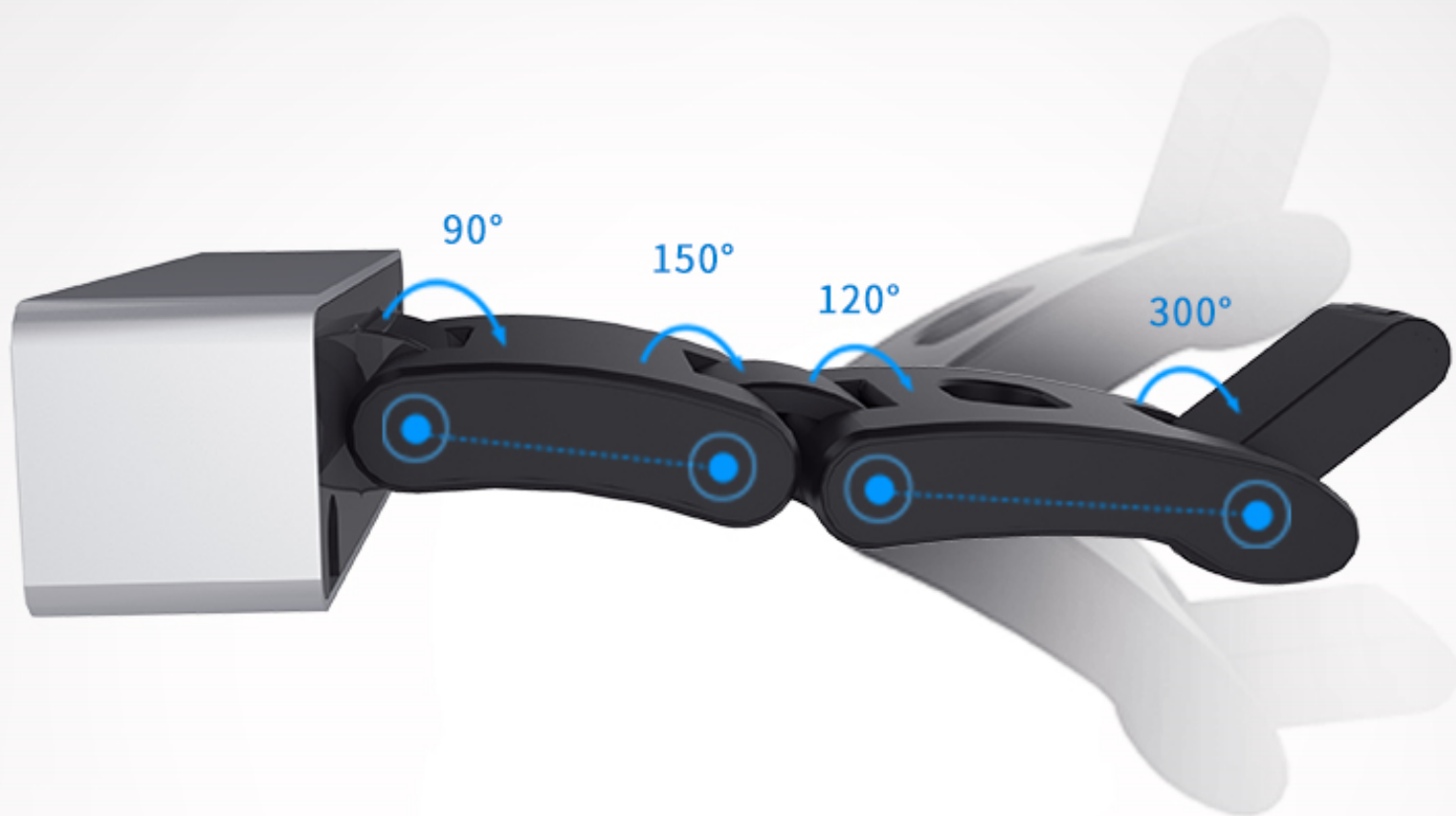

# 60° Wide Angle · Built-in 48dB Microphone


Easy to complete video conference



60°





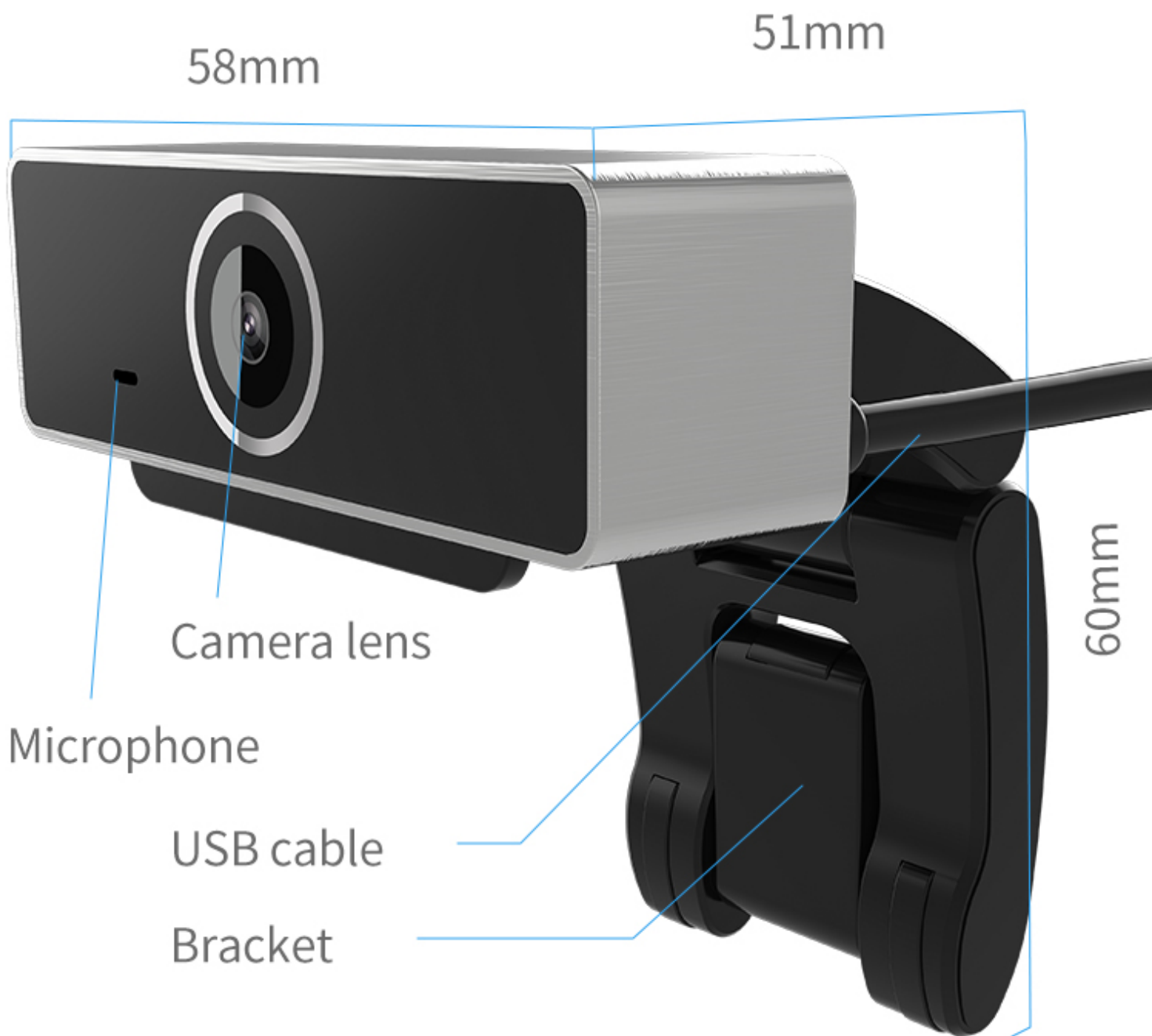

## Features



- 1/2.9" colour CMOS sensor
- Supports H.264 image compression
- Max resolution: 1920 x 1080
- Max image frame: 60fps
- Built-in 48 dB microphone
- Supports USB2.0\USB1.0, fast and full automatic switching
- Supports multiple Windows operating systems



## Specification

Image Sensor	1/2.9" Colour CMOS Sensor
Image Resolution	1920 x 1080 / 1280 x 720 / 640 x 360
Lens Type	6P+1R, F/NO 4.4 mm, EFL 2 mm, BFL 1 mm
Lens Angle	60°
Audio Format	USB Audio Support Class 1.0, ADC 16 bit
Microphone	Built-In 48 dB Microphone
Image Compression	H.264
Image Frame Rate	60 fps
Video Resolution	HD1080P (1920 x 1080 25fps), HD 720P (1280 x 720 30fps), VGA (640*480 60fps)
Operating Temperature	0 ... 55 °C
Operating Humidity	20 ... 85% Non Condensation
Storage Temperature	-10 ... 60 °C
Storage Humidity	0 ... 90% Non Condensation
Operating System	Windows10 32bit/64bit; Windows8 32bit/64bit; Windows7 32bit/64bit; Windows Vista 32bit/64bit; Windows XP SP2 32bit/64bit
Power Supply	DC 5 V

## Product Diagram

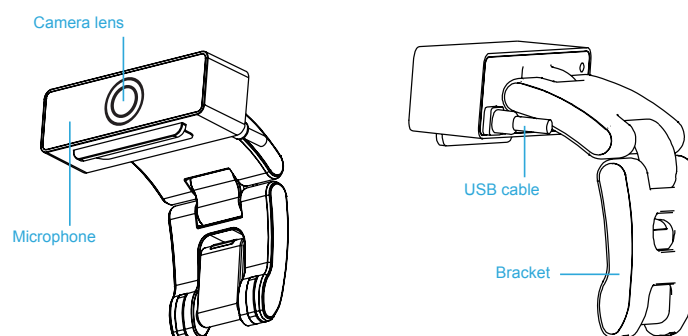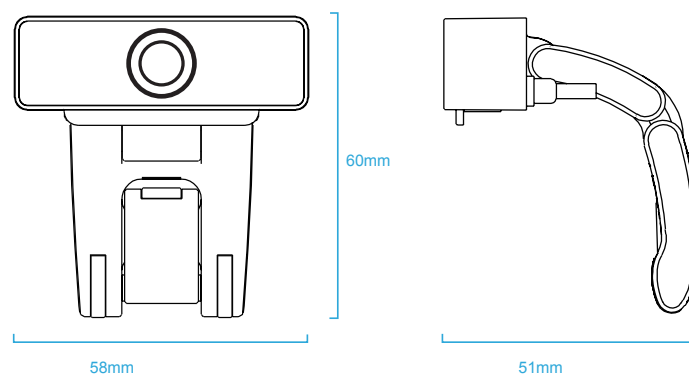

Art. Nr.  
RND 715-00006