

USB Headset with Mic and Mute Option



Features

- Adjustable over-the-head design for a comfortable fit that won't slip off
- Soft earpad, flexible and lightweight design ensures all-day comfort
- USB cable for simple, plug-and-play connectivity
- Microphone mute indicator light tells you when mute is enabled
- Advanced digital USB delivers superior sound quality



Headset Specification

Dimensions	135 x 50 x 165 mm
Weight	115 g
Operating Temperature	-10 ... 45 °C
Storage Temperature	-20 ... 60 °C


Headband Specification

Materials	h# ' " o ' U
o	.
O	' ' " ' k

Driver / Speaker Specification

Speaker Diameter	30 mm
Speaker Type	NdFeB
Impedance	32 Ω
Sound Pressure Level	100 \pm 3 dB / mW
L - R Two Speaker Balance	< 3 dB
Maximum Input Power	80 mW
Micro USB Charging Cable	300 mm
Audio Cable with Microphone	1.8 m
Microphone Sensitivity	57 \pm 3 dB
Frequency Range	20 Hz ... 20 kHz
Distortion	< 5% at 1 kHz

USB Headset with Mic and Mute Option

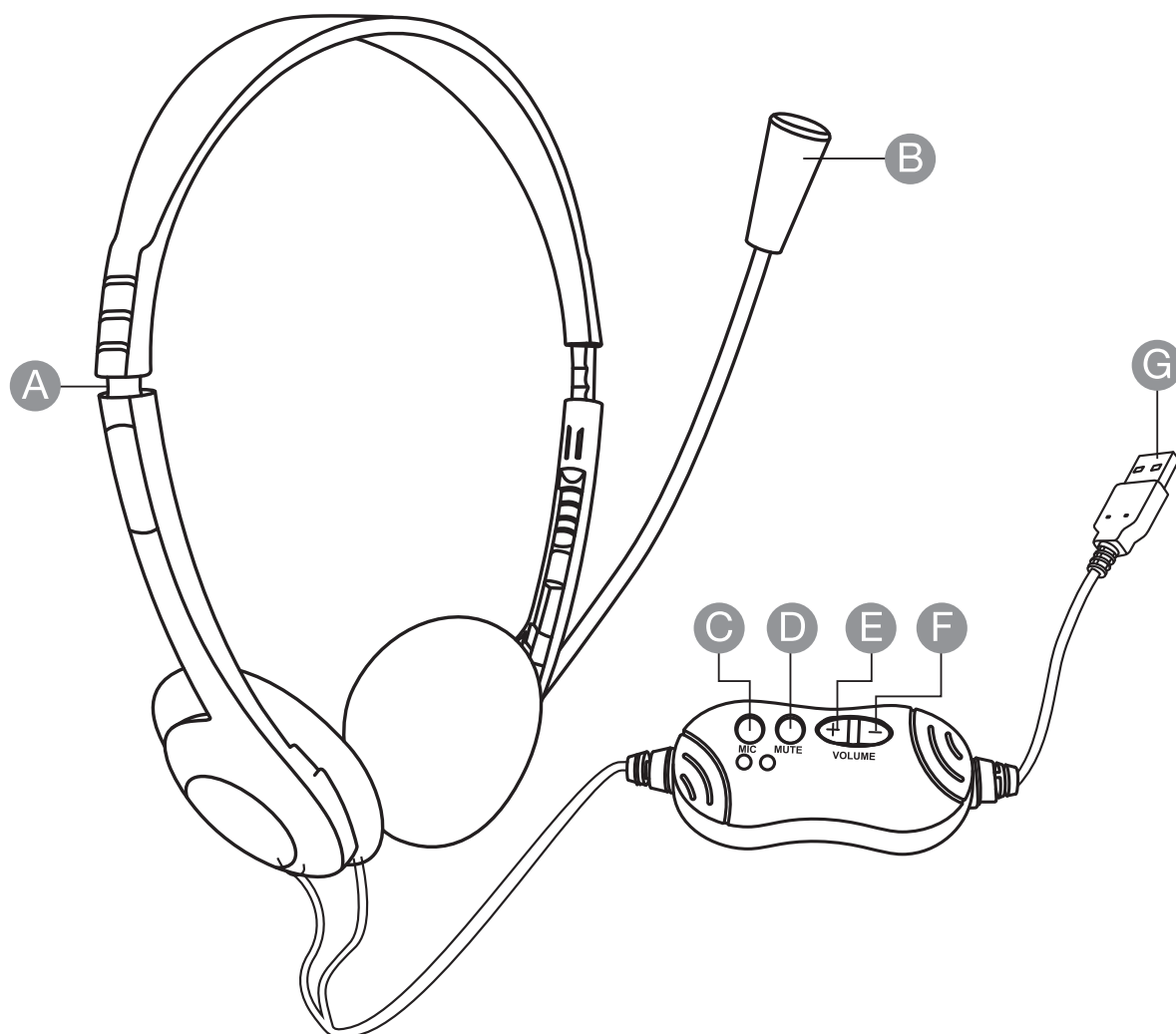

- A** Adjustable headband
- B** Microphone
- C** Microphone mute with red indicator
- D** Headphone mute with green indicator
- E** Volume up
- F** Volume down
- G** USB-A plug

*This illustration is for reference purposes only.

Art Nr.
RND 745-00001