


# USB A Plug to USB Mini-B 5-Pin Plug Cable

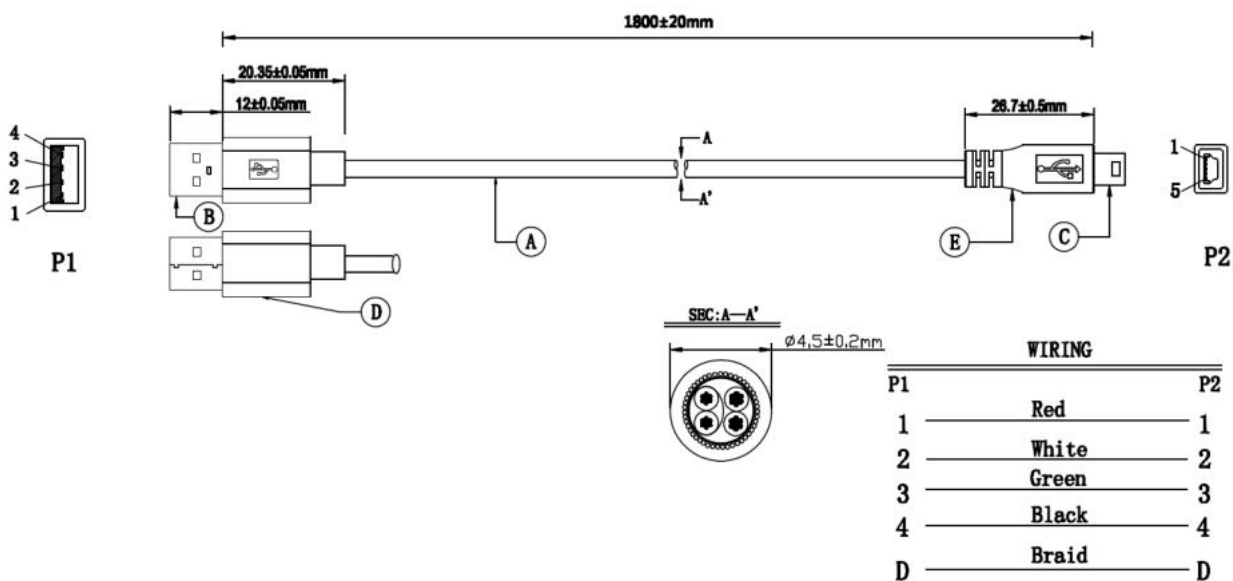

## SPECIFICATION:

Conductor Resistance	5ohm
Insulation Resistance	20Mohm min (DC300V/0.01s)
Length	1800±20mm
Molding (E)	45P PVC black
Inner Molding (D)	Transparent PE
Connector (C)	USB mini B/Male, nickel plated shell (iron, black PBT, copper)
Connector (B)	USB A Male, nickel plated shell (iron, black PBT, copper)
Cable (A)	28AWG (7/0.12BC+HDPE)*1P (green/white)+24AWG (7/0.2BC+HDPE)*2C(red/black)+AL-Foil+Braid (4/12-0.12AL-Mg) Jacket:OD4.5±0.2mm black PVC



Art. Nr.  
RND 765-00049