


USB A Plug to USB B Plug Cable

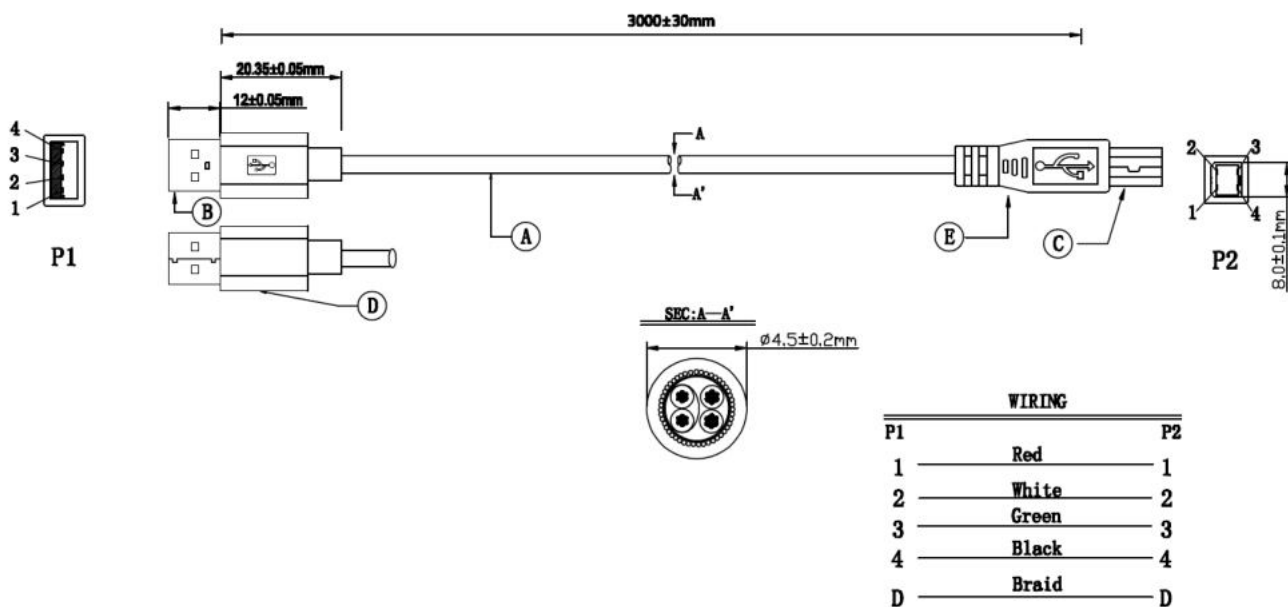

SPECIFICATION:

| | |
|-----------------------|---|
| Conductor Resistance | 5ohm |
| Insulation Resistance | 20Mohm min (DC300V/0.01s) |
| Length | 3000±30mm |
| Molding (E) | 45P PVC black |
| Inner Molding (D) | Transparent PE |
| Connector (C) | USB B Male, nickel plated shell (iron, black PBT, copper) |
| Connector (B) | USB A Male, nickel plated shell (iron, black PBT, copper) |
| Cable (A) | 28AWG (7/0.12BC+HDPE)*1P (green/white)+24AWG (7/0.2BC+HDPE)*2C(red/black)+AL-Foil+Braid (4/12-0.12AL-Mg) Jacket:OD4.5±0.2mm black PVC |



Art. Nr.
RND 765-00069