

# USB-C to USB-Lightning Cable



## Features


 
- USB 2.0 offering speeds of up to 480 Mbps
- All-copper conductors – for interference-free signal transmission
- Suitable for a wide range of applications
- Specially designed for durability and intended for intensive use



## Specification

Cable Design	Round
Connector A	USB-C Plug
Connector B	Apple Lightning
Cross-Section AWG	21 AWG
External Material	PVC
Function	Multi Sync and Charge
Jacket Colour	White
Length	2 m
Plating Material	Nickel
Speed Max. (Data)	480 Mbps
Standards Met	RoHS;REACH
USB Type	USB 2.0

## Drawing

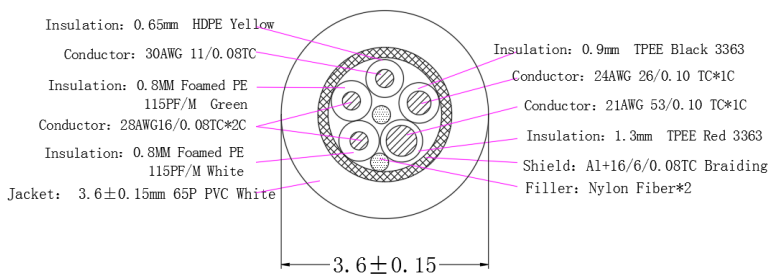



Type C Pin	Signal Name	color of cable	Lightning pin C94
A4, A9, B4, B9	USB Vbus	Red	1
A7	USB D-	White	2
A6	USB D+	Green	3
A5	CC	Yellow	4
A1, A12, B1, B12	DGND	Black	5
Shield	Shield	TC	Shield

100mF\*2

Art. Nr.  
RND 765-00310

# Drawing

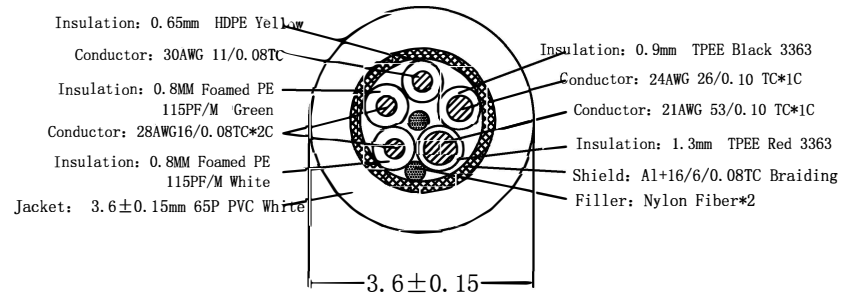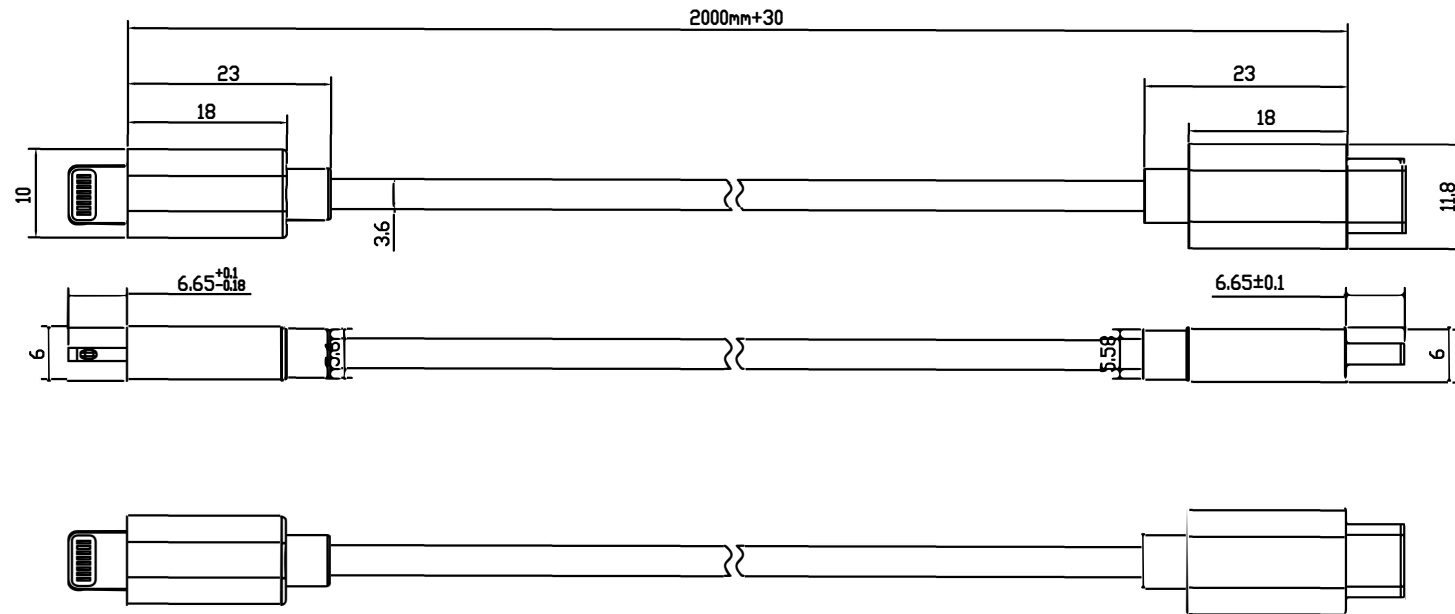

Wiring Diagram			
Type C Pin	Signal Name	color of cable	Lightning pin C94
A4, A9, B4, B9	USB Vbus	Red	1
A7	USB D-	White	2
A6	USB D+	Green	3
A5	CC	Yellow	4
A1, A12, B1, B12	DGND	Black	5
Shield	Shield	TC	Shield

Art. Nr.  
RND 765-00310