


## Features

- Circular mounts with centre hole
  - made of natural rubber
- Application:
- Bump stops
  - Industrial radiators
  - Instrument cases
  - Fuel tanker suspension
  - Flight equipment isolators
  - Vibration isolator for overhead suspension equipment
  - Building roof shock vibration isolators.

## RS PRO Anti-Vibration Pedestal Mount

RS Stock No.: 1263867, 1263866, 1263865, 1263863, 1263862, 1263861, 1263860, 1263859, 1263857, 1263856, 1263855

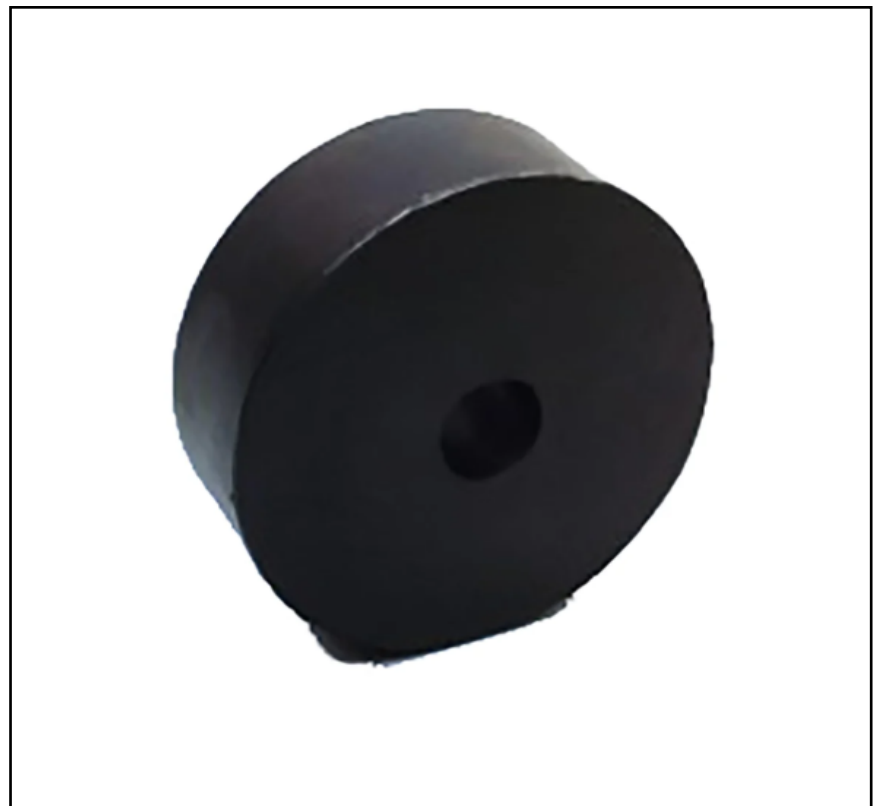

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

## Product Description

The KP series mounts are designed for vertical shock load damping for mobile and static equipment.

Colour: Black

Material: Natural Rubber

## Mechanical Specifications

RS Stock number	Description	L	H	A	F(m)	D	GD	S	G
1263867	Cyl Mnt 15mmOD x 15mm high x 6.5mm ID No metal plate 55 shA	-	15	-	-	15	-	-	6.5 mm
1263866	Cyl Mnt 20mmOD x 15mm high x 8.5mm ID No metal plate 55 shA	-	15	-	-	20	-	-	8.5 mm
1263865	Cyl Mnt 20mmOD x 20mm high x 8.5mm ID No metal plate 55 shA	-	20	-	-	20	-	-	8.5 mm
1263863	Cyl Mnt 20mmOD x 25mm high x 8.5mm ID No metal plate 55 shA	-	25	-	-	20	-	-	8.5 mm
1263862	Cyl Mnt 20mmOD x 30mm high x 8.5mm ID No metal plate 55 shA	-	30	-	-	20	-	-	8.5 mm
1263861	Cyl Mount 25mmOD x 10.5mmID x 15mm HT 50 shA	-	15	-	-	25	-	-	10.5 mm
1263860	Cyl Mount 25mmOD x 10.5mmID x 20mm HT 50 shA	-	20	-	-	25	-	-	10.5 mm
1263859	Cyl Mount 25mm OD x 10.5mm ID x 25mm HT 50 shA	-	25	-	-	25	-	-	10.5 mm
1263857	Cyl. Mtg 30mm OD x 30mm ID x 13.5mm high rubber only 50shA	-	30	-	-	30	-	-	13.5 mm
1263856	Cyl. Mtg 40mm OD x 30mm ID x 13.5mm high rubber only 50shA	-	30	-	-	40	-	-	13.5 mm
1263855	Cyl. Mtg 50mm OD x 30mm ID x 13.5mm high rubber only 50shA	-	30	-	-	50	-	-	17 mm

## Line Drawing -

