

Features

- FEMALE - FOOT/BUMP STOP
Cylindrical mounts, a simple and cost effective mount. For use in compression and shear. A very large range of available size

RS Pro Cylindrical Female - Foot Anti Vibration Mounts

RS Stock No.:

1265945,1265946,1265947,1265948,1263932,1265949,1265950,1265951,1265952,1265953,1265954,1265955,1265956,1263933,1263934,1265968,1265969,1266369,1263547




RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

A female to female bobbin isolation mount for use with engines and machinery for the vast reduction of vibration and protection of equipment. Cylindrical in shape with an M4 thread the anti-vibration bobbin is manufactured from natural rubber for excellent vibration absorption.

A simple to use and install anti-vibration mount achieving high shear and compression vibration damping and suitable for industrial environments.

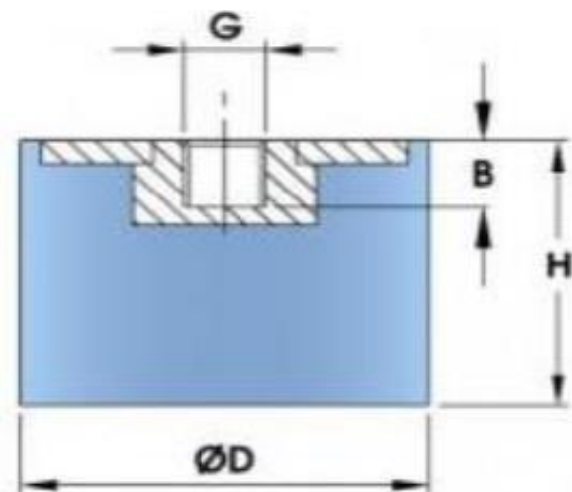

General Specifications

RS Code	Metal type	Rubber	Hardness	D (mm)	H (mm)	GxB (mm)
1265945	Zinc plated steel	Natural Rubber	60 Shore A	15	15	M4x4
1265946	Zinc plated steel	Natural Rubber	45 Shore A	16	10	M4x4
1265947	Zinc plated steel	Natural Rubber	60 Shore A	20	15	M6x6
1265948	Zinc plated steel	Natural Rubber	60 Shore A	20	17	M5x5
1263932	Stainless steel grade 304	Silicone Rubber	45 Shore A	20	20	M6x6
1265949	Zinc plated steel	Natural Rubber	60 Shore A	20	25	M6x6
1265950	Zinc plated steel	Natural Rubber	60 Shore A	20	30	M6x6
1265951	Zinc plated steel	Natural Rubber	50 Shore A	25	15	M8x8
1265952	Zinc plated steel	Natural Rubber	60 Shore A	25	22	M8x8
1265953	Zinc plated steel	Natural Rubber	50 Shore A	30	20	M8x8

1265954	Zinc plated steel	Natural Rubber	45 Shore A	30	22	M8x8
1265955	Zinc plated steel	Natural Rubber	45 Shore A	30	40	M6x6
1265956	Zinc plated steel	Natural Rubber	55 Shore A	40	15	M6x6
1263933	Stainless steel grade 304	Natural Rubber	55 Shore A	40	20	M8x8
1263934	Stainless steel grade 316	Natural Rubber	55 Shore A	40	25	M10x10
1265968	Zinc plated steel	Natural Rubber	50 Shore A	40	35	M8x8
1265969	Zinc plated steel	Natural Rubber	60 Shore A	50	15	M10x10
1266369	Zinc plated steel	Natural Rubber	60 Shore A	50	35	M10x10
1263547	Zinc plated steel	Natural Rubber	55 Shore A	75	55	M12x12