


FEATURES

- Light duty PVC flexible cord
- Manufactured to BS EN 50525-2-11
- 10 meter coil

RS PRO Power Cords

RS Stock No.: 2537002

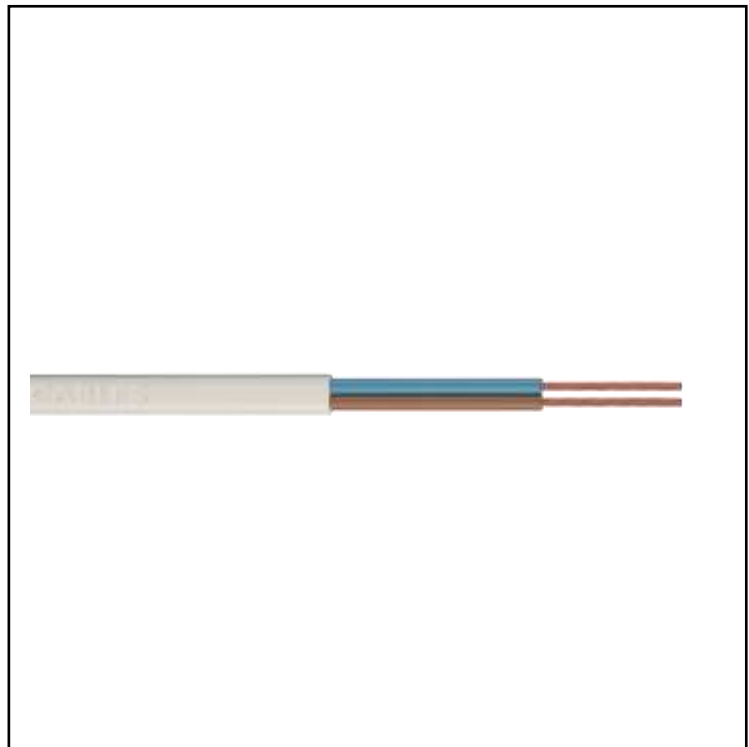

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

Flexible annealed copper conductor, PVC insulated, PVC sheathed light duty cords 300/300V circular twin

Light duty cords/flexibles are used where the risk of mechanical damage and mechanical stresses is low, i.e. under external influences to be expected in the normal use of light, hand-held appliances and light portable equipment in domestic premises, offices and shops.

Examples of appliances that need light duty cables include domestic hair dryers and hair styling appliances, radio sets, table and standard lamps and small desktop machines.

General Specifications

Conductor	Plain Annealed Copper Class 5 Flexible to BS EN 60228
Insulation	PVC Type T12 to BS EN 50363-3
Sheathing	PVC Type TM2 to BS EN 50363-4-1
Standard	BS EN 50525-2-11 Clause 4.1, Table B.1.
Number of conductors	2
Size of conductors	0.75mm ²

Mechanical Specifications

Minimum operating temperature	-15°C
Maximum operating temperature	70°C
Minimum bending radius	6 x diameter

Electrical Specifications

Voltage Rating	300/300V
Maximum Current rating	6 amperes

Approvals

Third party approvals	BASEC (British Approvals Service for Cables)
RoHS	RoHS Compliant

Similar Products

Stock No.	Brand	Product Name	Number and size of conductor	Length	Colour
2537001	RS PRO	2537001	2 x 0.75mm ²	5m	White