


## Features

- Operating temperature 40°C to +105°C.
- 100mm 1015 12AWG wire leads.
- Versatile application
- Cover for splash / debris protection.

## RS PRO Fuse Holders

RS Stock No.: 284-6489

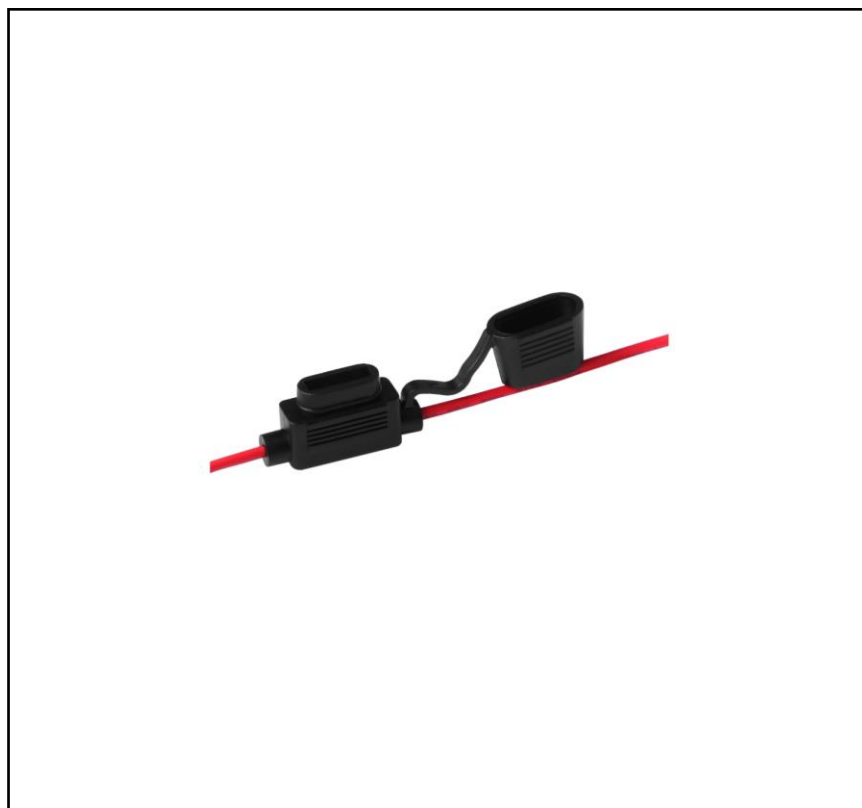

RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

## Product Description

*The in-line fuse holders are designed for versatile application of automotive fusing in harsh environments.*

*Standard 100mm 1015 12AWG wire leads on either side for inline installation.*

*Applications on accessory lighting, panel displays/electronics, air conditioner and blower motors.*

*Operating Temp: -40°C to +105°C.*

*Attached cover secures and protects installed fuse from splashes and debris.*

## General Specifications

Inline blade fuseholder	Apply for medium blade fuse
-------------------------	-----------------------------

## Mechanical Specifications

Total length	240mm
--------------	-------

## Electrical Specifications

Rating	30A32VDC
--------	----------

## Protection Category


IP	67
----	----

## Approvals

Declarations	MFR Declaration of Conformity
Standards Met	CE

## Drawing

Unit : mm

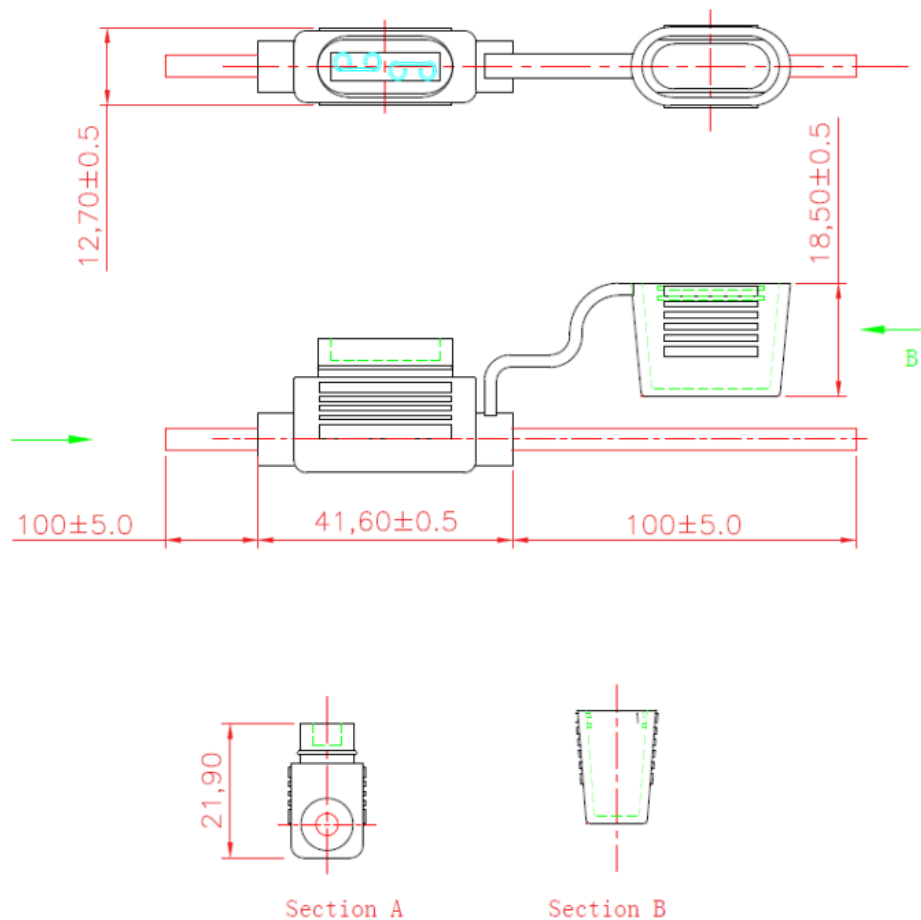

**Warning: If use above 32V, Power must be turn off when changing the fuse**