

## Features

- USB 3.0
- A - A
- M-F
- Black

## RS PRO USB 3.0 A-A M-F Extension Cable - Black

RS Stock No: 2862924, 2862925, 2862926, 2862927



RS Professionally Approved Products bring to you, professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

## Product Description

The RS PRO range of "SuperSpeed USB 3.0 " Type A (male) to Type A (female) Extension cables support a data transfer rate up to 5 Gbit/s (625 MB/s), which is about ten times faster than USB 2.0 technology. This is a standard Type A to A Female Extension Cable; it is designed to extend an already existing cable.

The official name for this cable would be USB3.2 Gen 1. (Previously known as USB3.1 Gen 1 and USB 3.0)

## General Specifications



USB Type	USB 3.0
Connector A	Male USB A
Connector A Type	USB 3.0
Connector A Gender	Male
Connector B	Female USB A
Connector B Type	USB 3.0
Connector B Gender	Female
Connector Style	Straight
Data Transfer Rate	5Gbps
Outer Sheath Material	PVC
Sheath Colour	Black
Connector Plating	Nickel
Pin Construction	Copper

## Approvals

Standards Met	CE UKCA ROHS REACH
Declarations	CE UKCA ROHS REACH

## Similar Products

Stock No.	Length	Spec	Colour
2862924	1mtr	USB3.0 A-M to Type A-F Extension Cable	Black
2862925	2mtr	USB3.0 A-M to Type A-F Extension Cable	Black
2862926	3mtr	USB3.0 A-M to Type A-F Extension Cable	Black
2862927	5mtr	USB3.0 A-M to Type A-F Extension Cable	Black

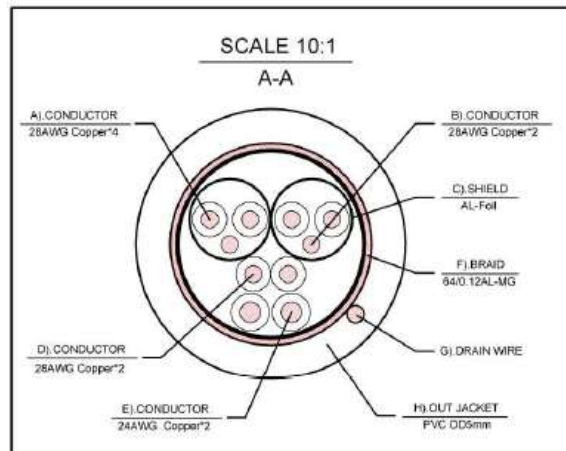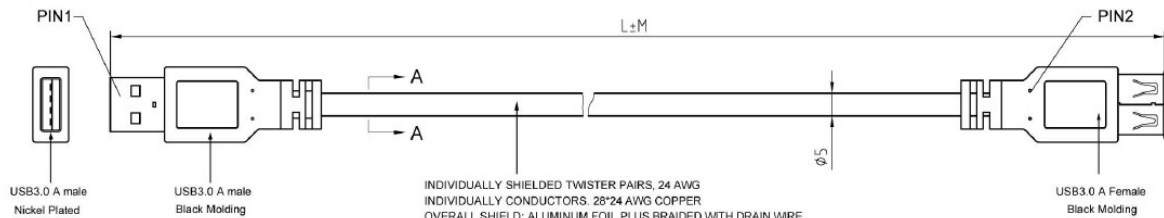

### Notes:

1. CABLE ASSEMBLY SHALL BE TESTED FOR CONTINUITY
2. USB3.0 CABLE 24AWG COPPER, OUTER JACKET OD=5MM
3. HOOD:MOLDING TYPE, BLACK IN COLOR
4. BOTH SIDES INNER MOLD MATERIAL PE.
5. CABLE ELECTRICAL TEST:  
100% OPEN SHORAR AND MIS-WIRE TEST