


SCHRAUBEN UND MUTTERN AUS NYLON

Zylinderschrauben mit Schlitz

SR 1951

Nylon 6.6, natur

- Maßtoleranzen ähnlich ISO 1207, NF E 25-127, DIN 84

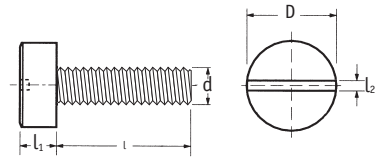

Artikelnummer	Maße (mm)					Stück/VPE
	d	l	D	l ₁	l ₂	
0010010000VR	M2 x 0.4	4.0	3.8	1.3	0.5	1000
0010020000VR	M2 x 0.4	5.0	3.8	1.3	0.5	1000
0010030000VR	M2 x 0.4	6.0	3.8	1.3	0.5	1000
0010040000VR	M2 x 0.4	8.0	3.8	1.3	0.5	1000
0011450000VR	M2 x 0.4	10.0	3.8	1.3	0.5	1000
0011380000VR	M2 x 0.4	12.0	3.8	1.3	0.7	1000
0011370000VR	M2 x 0.4	16.0	3.8	1.3	0.7	1000
0011320000VR	M2 x 0.4	20.0	3.8	1.3	0.7	1000
0011330000VR	M2 x 0.4	25.0	3.8	1.3	0.7	1000
0011350000VR	M2.5 x 0.45	6.0	4.5	1.6	0.6	1000
0011500000VR	M2.5 x 0.45	8.0	4.5	1.6	0.6	1000
0011460000VR	M2.5 x 0.45	10.0	4.5	1.6	0.6	1000
0011640000VR	M2.5 x 0.45	12.0	4.5	1.6	0.6	1000
0011310000VR	M2.5 x 0.45	16.0	4.5	1.6	0.6	1000
0011430000VR	M2.5 x 0.45	20.0	4.5	1.6	0.8	1000
0011440000VR	M2.5 x 0.45	25.0	4.5	1.6	0.8	1000
0010060000VR	M3 x 0.5	4.0	5.5	2.0	0.8	1000
0011390000VR	M3 x 0.5	5.0	5.5	2.0	0.8	1000
0010070000VR	M3 x 0.5	6.0	5.5	2.0	0.8	1000
0010080000VR	M3 x 0.5	8.0	5.5	2.0	0.8	1000
0010090000VR	M3 x 0.5	10.0	5.5	2.0	0.8	1000
0010100000VR	M3 x 0.5	12.0	5.5	2.0	0.8	1000
0010120000VR	M3 x 0.5	16.0	5.5	2.0	0.8	1000
0010130000VR	M3 x 0.5	20.0	5.5	2.0	0.8	1000
0010140000VR	M3 x 0.5	25.0	5.5	2.0	0.8	1000
0010150000VR	M3 x 0.5	30.0	5.5	2.0	0.8	1000
0011780000VR	M3 x 0.5	35.0	6.0	2.4	1.0	1000
0011790000VR	M3 x 0.5	40.0	6.0	2.4	1.0	1000
0010160000VR	M4 x 0.7	6.0	7.0	2.6	1.2	1000
0010170000VR	M4 x 0.7	8.0	7.0	2.6	1.2	1000
0010180000VR	M4 x 0.7	10.0	7.0	2.6	1.2	1000
0010190000VR	M4 x 0.7	12.0	7.0	2.6	1.2	1000
0010210000VR	M4 x 0.7	16.0	7.0	2.6	1.2	1000
0010220000VR	M4 x 0.7	20.0	7.0	2.6	1.2	1000
0010230000VR	M4 x 0.7	25.0	7.0	2.6	1.2	1000
0010240000VR	M4 x 0.7	30.0	7.0	2.6	1.2	1000
0010250000VR	M4 x 0.7	40.0	7.0	2.6	1.2	1000
0010260000VR	M5 x 0.8	6.0	8.5	3.3	1.2	1000
0010270000VR	M5 x 0.8	8.0	8.5	3.3	1.2	1000
0010280000VR	M5 x 0.8	10.0	8.5	3.3	1.2	1000
0010290000VR	M5 x 0.8	12.0	8.5	3.3	1.2	1000
0010310000VR	M5 x 0.8	16.0	8.5	3.3	1.2	1000
0010330000VR	M5 x 0.8	20.0	8.5	3.3	1.2	1000
0010340000VR	M5 x 0.8	25.0	8.5	3.3	1.2	1000
0010350000VR	M5 x 0.8	30.0	8.5	3.3	1.2	1000

Artikelnummer	Maße (mm)					Stück/VPE
	d	l	D	l ₁	l ₂	
0010360000VR	M5 x 0.8	40.0	8.5	3.3	1.2	1000
0010370000VR	M5 x 0.8	50.0	8.5	3.3	1.2	1000
0011800000VR*	M5 x 0.8	60.0	8.5	3.3	1.2	1000
0010380000VR*	M5 x 0.8	70.0	8.5	3.3	1.2	1000
0010390000VR	M6 x 1.0	6.5	10.0	3.9	1.6	1000
0010410000VR	M6 x 1.0	8.0	10.0	3.9	1.6	1000
0010420000VR	M6 x 1.0	10.0	10.0	3.9	1.6	1000
0010430000VR	M6 x 1.0	12.0	10.0	3.9	1.6	1000
0010450000VR	M6 x 1.0	16.0	10.0	3.9	1.6	1000
0010460000VR	M6 x 1.0	20.0	10.0	3.9	1.6	1000
0010470000VR	M6 x 1.0	22.0	10.0	3.9	1.6	1000
0010480000VR	M6 x 1.0	25.0	10.0	3.9	1.6	1000
0010500000VR	M6 x 1.0	30.0	10.0	3.9	1.6	1000
0010520000VR	M6 x 1.0	40.0	10.0	3.9	1.6	1000
0010530000VR	M6 x 1.0	50.0	10.0	3.9	1.6	1000
0010550000VR	M6 x 1.0	60.0	10.0	3.9	1.6	1000
0011280000VR	M6 x 1.0	70.0	10.0	3.9	1.6	500
0010570000VR	M6 x 1.0	80.0	10.0	3.9	1.6	1000
0010640000VR	M8 x 1.25	8.0	13.0	5.0	2.0	1000
0010650000VR	M8 x 1.25	10.0	13.0	5.0	2.0	1000
0010680000VR	M8 x 1.25	16.0	13.0	5.0	2.0	1000
0010690000VR	M8 x 1.25	20.0	13.0	5.0	2.0	1000
0010700000VR	M8 x 1.25	25.0	13.0	5.0	2.0	1000
0010710000VR	M8 x 1.25	30.0	13.0	5.0	2.0	1000
0010720000VR	M8 x 1.25	35.0	13.0	5.0	2.0	1000
0010730000VR	M8 x 1.25	40.0	13.0	5.0	2.0	1000
0010740000VR	M8 x 1.25	50.0	13.0	5.0	2.0	500
0010750000VR	M8 x 1.25	60.0	13.0	5.0	2.0	500
0011480000VR	M8 x 1.25	70.0	13.0	5.0	2.0	500
0010770000VR	M8 x 1.25	80.0	13.0	5.0	2.0	100
0011850000VR	M10 x 1.5	16.0	16.0	6.0	2.5	500
0010860000VR	M10 x 1.5	20.0	16.0	6.0	2.5	500
0010880000VR	M10 x 1.5	30.0	16.0	6.0	2.5	500
0010890000VR	M10 x 1.5	40.0	16.0	6.0	2.5	500
0010900000VR	M10 x 1.5	50.0	16.0	6.0	2.5	250
0010910000VR	M10 x 1.5	60.0	16.0	6.0	2.5	250
0010920000VR	M10 x 1.5	70.0	16.0	6.0	2.5	250
0010930000VR	M10 x 1.5	80.0	16.0	6.0	2.5	250
0011020000VR	M12 x 1.75	40.0	19.0	8.0	2.5	500
0011030000VR	M12 x 1.75	50.0	19.0	8.0	2.5	1000
0011860000VR	M16 x 2.0	40.0	23.0	9.5	4.5	500
0011180000VR	M16 x 2.0	50.0	23.0	9.5	4.5	250

* mit Teilgewinde

FÜR SCHWARZE ZYLINDERSCHRAUBEN MIT SCHLITZ SIEHE UMSEITIG