


# LCD Monitor Stand, Tempered Glass Surface Risers (Square) with adjustable metal feet

<b>Product No.</b>	17.02.3376
<b>Manufacturer</b>	ROLINE
<b>Manufacturer No.</b>	17.02.3376
<b>EAN (single piece)</b>	7611990148462

**roline**  
Designed for Professionals

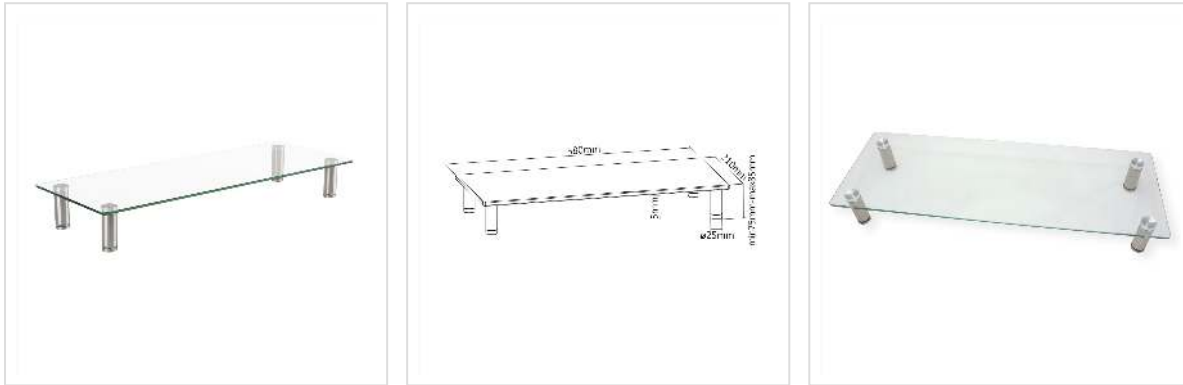

**High-quality, height-adjustable glass table with a load capacity of up to 20 kg. There is a thread in the well designed metal feet with which the glass table can be perfectly adjusted for each surface.**

- Compact design with smooth edges all around
- Increased storage room beneath the desktop
- Create extra storage (ca. 500 x 210 mm) for your keyboard or documents and office stationery under the platform; besides the placed monitor, there is an additional room, e.g. for speakers or other technical devices
- Stepless height settings for your free height adjustment (75 - 85 mm)
- Max. loading: 20 kg
- Dimensions of stand (LxWxH): 580 x 210 x 75 - 85 mm

Suggested Screen Size: up to 81cm (13"-32")

Max. Load: 20 kg

Adjustable Height: 75mm - 85mm

Glass Thickness: 5mm

Material: Glass, Stainless Steel

Dimensions: 580 x 210 x 85mm

## Technical specifications

Manufacturer: ROLINE

Product group: LCD-Monitor arms

Product type	Monitor stand
--------------	---------------

Colour	silver
--------	--------

Load capacity	20 kg
---------------	-------

Number of monitors	1
--------------------	---

Material group	Glass
----------------	-------

height	85 mm
--------	-------

width	580 mm
-------	--------

depth	210 mm
-------	--------

Weight	1739.5 g
--------	----------