

Solid cores

Kiinteät ytimet » Сердечники цельнорезиновые » Solida kärnor » Nuclei centrali





Ø 28

Ø 48

Ø 68

FI	Ydin	Ulkomitat (mm) Ø (D = 60 mm)	(kg)	Paino (lb)	Tuotenumero
RU	Сердечник	Наруж. диаметр (мм) Ø (D = 60 мм)	(кг)	Вес (фунт)	Арт. №
SE	Kärna	Yttermått (mm) Ø (D = 60 mm)	(kg)	Vikt (lb)	Artikelnummer
IT	Nucleo	Dim. esterne (mm) Ø (D = 60 mm)	(kg)	Peso (lb)	Art.Nr.
EN	Core	External dim. (mm) Ø (D=60 mm)	(kg)	Weight (lb)	Art No.
	Ø 28	28	0.05	0.106	MC00028601900
	Ø 48	48	0.16	0.355	MC00048601900
	Ø 68	68	0.32	0.697	MC00068601900

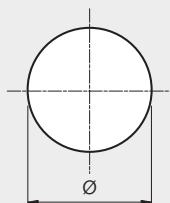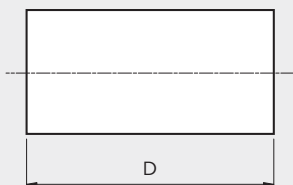

Pos	(mm)	(in)
D	60	2.362

Note: All dimensions are nominal values
 Huomaa: Kaikki mitat ovat nimellisarvoja
 Внимание: Все размеры номинальные
 Obs: Alla mått är nominella
 Nota: tutte le dimensioni sono valori nominali