

# DYMO®

## LabelManager™ 210D




### CREATE LABELS FAST WITH SMART KEYS

Customize labels using Computer-style keyboard and one-touch Smart Keys for fast formatting

#### Features

- Large LCD display
- Computer-style keyboard
- One-touch Smart Keys for fast formatting
- Long lasting rechargeable battery pack
- 20+ ways to format text
- 200+ symbols and clip-art images
- Print up to 1/2 in (12 mm) wide labels

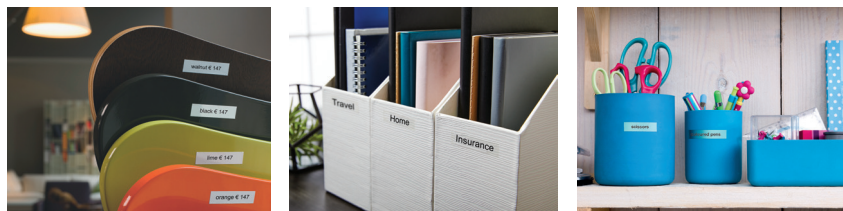

#### Single Unit Includes:

- LabelManager 210D
- D1 Starter Label Cassette, 12mm x 3m Black On White
- Quick Start Guide
- 2 + 1 - Year Limited Warranty\*



#### Quick Specs

|                             |                                 |
|-----------------------------|---------------------------------|
| Unit Dimensions (H x W x L) | 155 x 165 x 64 mm               |
| Weight (excluding battery)  | 435 g                           |
| Mac®/PC Compatible          | No                              |
| Accepts Label Sizes         | 6mm, 9mm and 12mm               |
| Tape Platform               | D1, Durables                    |
| Resolution                  | 180 dpi                         |
| Printing System             | Thermal Transfer                |
| Print Speed                 | 12 mm/sec                       |
| Barcodes                    | No                              |
| Cutter Type                 | Manual                          |
| Batteries                   | 6 AA (not included)             |
| Adapter                     | Yes (optional, sold separately) |
| Networking                  | No                              |
| Country of Origin           | China                           |


| Item Number                       | Description             |      | Length (cm) | Width (cm) | Height (cm) | QTY | EAN           | Customer Price |
|-----------------------------------|-------------------------|------|-------------|------------|-------------|-----|---------------|----------------|
| S0784460                          | LabelManager 210D AZERT | Unit | 9.7         | 22.2       | 20.3        | 1   | 3501170784464 |                |
| <b>Accessories (www.dymo.com)</b> |                         |      |             |            |             |     |               |                |
| S0721430                          | Charging Adapter        | Unit | 11.5        | 6.0        | 9.0         | 1   | -             |                |

\* +1 year if registered on the DYMO® website

## D1 Standard Polyester Labels

For hundreds of tasks around the office or home office, such as filing, storage and asset tracking.  
Temperature rating: -18°C to 90°C

| D1 STANDARD LABELS (3 m)     | 6 mm     | 9 mm     | 12 mm    |
|------------------------------|----------|----------|----------|
| ABC                          | -        | -        | 2084349  |
| ABC                          | -        | -        | 2084401  |
| D1 STANDARD LABELS (7 m)     | 6 mm     | 9 mm     | 12 mm    |
| ABC                          | S0720780 | S0720680 | S0720530 |
| ABC                          | S0720770 | S0720670 | S0720500 |
| ABC                          | S0720790 | S0720730 | S0720580 |
| ABC                          | -        | S0720710 | S0720560 |
| ABC                          | -        | S0720740 | S0720590 |
| ABC                          | -        | S0720720 | S0720570 |
| ABC                          | -        | -        | S0720610 |
| ABC                          | -        | S0720690 | S0720540 |
| ABC                          | -        | -        | S0720510 |
| ABC                          | -        | -        | S0720600 |
| ABC                          | -        | S0720700 | S0720550 |
| ABC                          | -        | -        | S0720520 |
| D1 STANDARD MULTIPACKS (7 m) | 6 mm     | 9 mm     | 12 mm    |
| ABC                          | -        | 2093096  | 2093097  |

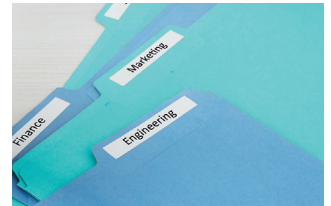

## D1 Durable Vinyl Labels

Industrial strength adhesive helps to ensure labels stay stuck to a variety of surfaces.  
Temperature rating: -40°C to 80°C

| D1 DURABLE LABELS (3 m)   | 12 mm   |
|---------------------------|---------|
| ABC                       | 1978366 |
| ABC                       | 1978365 |
| ABC                       | 1978367 |
| D1 DURABLE LABELS (5.5 m) | 12 mm   |
| ABC                       | 1978364 |



## D1 Permanent Polyester Labels

Professional, polished finish ideal for panels, blocks, faceplates, shelves, bins and more.  
Temperature rating: -40°C to 150°C\*

| D1 PERMANENT POLYESTER (5.5 m) | 12 mm    |
|--------------------------------|----------|
| ABC                            | S0718060 |

\*depends on surface



## D1 Flexible Nylon Labels

Specifically designed for curved surfaces and wire and cable marking.  
Temperature rating: -40°C to 60°C

| D1 FLEXIBLE NYLON (3.5 m) | 12 mm    |
|---------------------------|----------|
| ABC                       | S0718040 |



The DYMO® high quality labels are made in Belgium