

3M Science.
Applied to Life.™


Safety that's just your style.

Comfortable, stylish eyewear with a vast array of colour and lens tint options, the 3M™ Solus™ 2000 Series provides the eye protection you need with the style you want.

Solus™ Series—so cool, so comfortable, so you.

3M™ Solus™ 2000 Series

The 3M™ Solus™ 2000 Series features adjustable ratchet temples that allow the wearer to customise. Choose from several lens coating options, including 3M™ Scotchgard™ Anti-Fog, multiple lens Colours and features like a removable foam gasket to create your best protective eyewear solution.

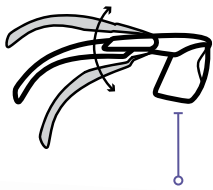

Adjustable Ratchet Temples
Multiple position ratchet allows user to adjust lens for facial features and eyeglass position.



Removable Foam-lined Gasket
Helps limit eye exposure to dirt and debris while providing added comfort and cushioning (selected models).



Polycarbonate Lens

- ▶ Absorb 99.9% of UVA and UVB rays.
- ▶ Meet the requirements of EN166:2001 Standard as an Impact Rated Spectacle.

Choose Your Coating

- ▶ Scotchgard™ Anti-Fog Coating provides fog and abrasion resistance (selected models).
- ▶ Models with anti-scratch coating also available.



S2001ASP-BLU
Lens: Clear | Frame Colour: Blue/Grey



S2001AF-BLU
Lens: Clear | Frame Colour: Blue/Grey



S2001SGAF-RED
Lens: Clear | Frame Colour: Grey/Red



S2002SGAF-RED
Lens: Grey | Frame Colour: Grey/Red



S2024AS-RED
Lens: Red Mirror | Frame Colour: Grey/Red



S2001SGAF-BGR
Lens: Clear | Frame Colour: Grey/Blue-Green



S2002SGAF-BGR
Lens: Grey | Frame Colour: Grey/Blue-Green



S2003SGAF-BGR
Lens: Amber | Frame Colour: Grey/Blue-Green



S2005SGAF-BGR
Lens: Brown | Frame Colour: Grey/Blue-Green



S2007SGAF-BGR
Lens: I/O Grey | Frame Colour: Grey/Blue-Green



Foam gasket
S2001SGAF-BGR-F
Lens: Clear | Frame Colour: Grey/Blue-Green

Readers and IR Shade models due end 2019
3x reader pairs +1.5, +2, +2.5 and 3x IR pairs IR 1.7, IR 3 and IR 5

3M™ Solus™ 2000 Series

Product ID	3M ID	Description	Lens colour	Frame colour	Coating	Units per case	Foam gasket
S2001ASP-BLU	XA006510961	3M™ Solus™ 2000 Safety Glasses, Blue/Grey Temples, Clear Anti-Scratch+ (K), Clear Lens, S2001ASP-BLU-EU	Clear	Blue/grey	AS+	20	
S2001AF-BLU	XA006510979	3M™ Solus™ 2000 Safety Glasses, Blue/Grey Temples, Anti-Fog/Anti-Scratch, Clear Lens, S2001AF-BLU-EU	Clear	Blue/grey	AS/AF	20	
S2001SGAF-RED	XA006510870	3M™ Solus™ 2000 Safety Glasses, Grey/Red Temples, Scotchgard™ Anti-Fog (K&N), Clear Lens, S2001SGAF-RED-EU	Clear	Grey/red	SGAF	20	
S2002SGAF-RED	XA006510888	3M™ Solus™ 2000 Safety Glasses, Grey/Red Temples, Scotchgard™ Anti-Fog (K&N), Grey Lens, S2002SGAF-RED-EU	Grey	Grey/red	SGAF	20	
S2024AS-RED	XA006510896	3M™ Solus™ 2000 Safety Glasses, Grey/Red Temples, Anti-Scratch, Red Mirror Lens, S2024AS-RED-EU	Red mirror	Grey/red	AS	20	
S2001SGAF-BGR	XA006510904	3M™ Solus™ 2000 Safety Glasses, Grey/Blue-Green Temples, Scotchgard™ Anti-Fog (K&N), Clear Lens, S2001SGAF-BGR-EU	Clear	Grey/blue-green	SGAF	20	
S2002SGAF-BGR	XA006510912	3M™ Solus™ 2000 Safety Glasses, Grey/Blue-Green Temples, Scotchgard™ Anti-Fog (K&N), Grey Lens, S2002SGAF-BGR-EU	Grey	Grey/blue-green	SGAF	20	
S2003SGAF-BGR	XA006510920	3M™ Solus™ 2000 Safety Glasses, Grey/Blue-Green Temples, Scotchgard™ Anti-Fog (K&N), Amber Lens, S2003SGAF-BGR-EU	Amber	Grey/blue-green	SGAF	20	
S2005SGAF-BGR	XA006510938	3M™ Solus™ 2000 Safety Glasses, Grey/Blue-Green Temples, Scotchgard™ Anti-Fog (K&N), Brown Lens, S2005SGAF-BGR-EU	Brown	Grey/blue-green	SGAF	20	
S2007SGAF-BGR	XA006510946	3M™ Solus™ 2000 Safety Glasses, Grey/Blue-Green Temples, Scotchgard™ Anti-Fog (K&N), I/O Grey Lens, S2007SGAF-BGR-EU	I/O Grey	Grey/blue-green	SGAF	20	
S2001SGAF-BGR-F	XA006510953	3M™ Solus™ 2000 Safety Glasses, Grey/Blue-Green Temples, Foam Gasket, Scotchgard™ Anti-Fog (K&N), Clear Lens, S2001SGAF-BGR-F-EU	Clear	Grey/blue-green	SGAF	20	✓

Explore more protective eyewear at 3m.co.uk/Solus2000

#3MScienceofSafety

IMPORTANT NOTICE

The use of the 3M product described within this document assumes that the user has previous experience of this type of product and that it will be used by a competent professional. Before any use of this product it is recommended to complete some trials to validate the performance of the product within its expected application.

All information and specification details contained within this document are inherent to this specific 3M product and would not be applied to other products or environment. Any action or usage of this product made in violation of this document is at the risk of the user.

Compliance to the information and specification relative to the 3M product contained within this document does not exempt the user from compliance with additional guidelines (safety rules, procedures). Compliance to operational requirements especially in respect to the environment and usage of tools with this product must be observed. The 3M group (which cannot verify or control those elements) would not be held responsible for the consequences of any violation of these rules which remain external to its decision and control.

Warranty conditions for 3M products are determined with the sales contract documents and with the mandatory and applicable clause, excluding any other warranty or compensation.

3M Personal Safety Division 3M United Kingdom PLC

3M Centre
Cain Road, Bracknell
Berkshire RG12 8HT
t: 0870 60 800 60
www.3m.eu/safety

3M Ireland Limited
The Iveagh Building
The Park, Carrickmines
Dublin 18
t: 1800 320 500

Please recycle. Printed in the UK. 3M and Scotchgard are trademarks of 3M Company. © 3M 2019. All rights reserved.

OFN629 Version Solus 2000.1

This version is the sole document applicable to the product(s) since its date of publication.

