



## Fittings for metallic conduits

### SC-FM Fixed external thread, IP40

Fixed external thread, nickel plated brass.


#### Features and benefits

- Two-part fitting of shell and body with external thread
- Provides tight, reliable hold of conduit
- Can be secured with locknut



HeliaGuard SC-FM Fixed External Thread.

<b>MATERIAL</b>	Nickel Plated Brass (NPB)
<b>Operating Temperature</b>	-100 °C to +300 °C

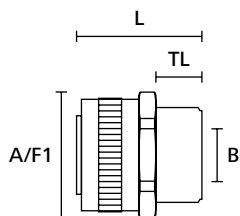

HeliaGuard fitting, straight with fixed external thread

TYPE	Nominal Ø	Thread Size	Min. Bore Size (B)	Length (L)	A/F Body (A/F1)	Thread Length (TL)	Pack Cont.	Colour	Article-No.
SC10-FM-M12	10	M12	5.6	21.0	13	7.0	10 pcs.	Metal (ML)	166-30300
SC10-FM-PG7	10	PG7	5.6	21.0	13	8.0	10 pcs.	Metal (ML)	166-30311
SC12-FM-M16	12	M16	8.5	23.0	17	10.0	10 pcs.	Metal (ML)	166-30301
SC16-FM-M16	16	M16	11.5	25.0	20	10.0	10 pcs.	Metal (ML)	166-30302
SC16-FM-M20	16	M20	11.5	25.0	22	10.0	10 pcs.	Metal (ML)	166-30303
SC16-FM-PG11	16	PG11	11.5	25.0	22	10.0	10 pcs.	Metal (ML)	166-30314
SC20-FM-M20	20	M20	15.3	26.3	24	10.0	10 pcs.	Metal (ML)	166-30304
SC20-FM-PG16	20	PG16	15.3	26.3	24	10.0	10 pcs.	Metal (ML)	166-30315
SC25-FM-M25	25	M25	19.1	29.5	29	10.0	10 pcs.	Metal (ML)	166-30305
SC25-FM-PG21	25	PG21	19.1	32.5	29	12.0	10 pcs.	Metal (ML)	166-30316
SC32-FM-M32	32	M32	26.2	36.8	36	13.0	2 pcs.	Metal (ML)	166-30306
SC32-FM-PG29	32	PG29	26.2	36.8	38	13.0	2 pcs.	Metal (ML)	166-30317
SC40-FM-M40	40	M40	34.6	39.0	48	14.0	2 pcs.	Metal (ML)	166-30307
SC40-FM-PG36	40	PG36	34.2	39.0	48	14.0	2 pcs.	Metal (ML)	166-30318
SC50-FM-M50	50	M50	44.7	42.0	58	15.0	1 pc.	Metal (ML)	166-30308
SC50-FM-PG42	50	PG42	44.8	42.0	58	15.0	1 pc.	Metal (ML)	166-30319
SC63-FM-M63	63	M63	54.1	50.0	70	18.0	1 pc.	Metal (ML)	166-30309
SC63-FM-PG48	63	PG48	54.5	48.0	70	16.0	1 pc.	Metal (ML)	166-30320
SC75-FM-M75	75	M75	66.4	60.0	84	20.0	1 pc.	Metal (ML)	166-30310

All dimensions in mm. Subject to technical changes.  
Minimum Order Quantity (MOQ) may differ from package content.

