


# Deep groove ball bearings, single row, shield on both sides



Principal dimensions			Basic load ratings		Fatigue load limit $P_u$	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
17	26	5	1,68	0,93	0,039	56000	28000	0,0082	61803-2Z

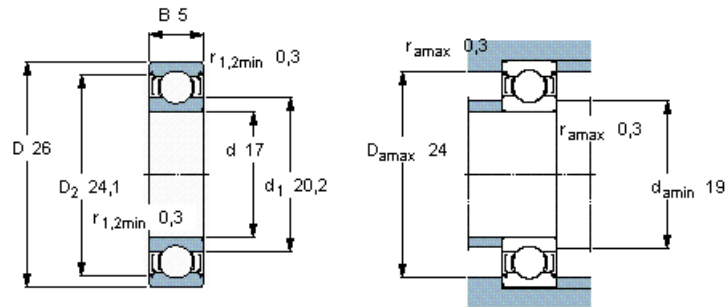

### Calculation factors

$k_r = 0,015$

$f_0 = 10$