

**Keyword:**  
 iXtra - Long Term High Performance


<b>Model:</b>	<b>SL-761</b>
<b>Performance Data</b> (Typical values for batteries stored at 25 °C for one year)	<b>Size 2/3AA</b>
System	Li/SOCl <sub>2</sub>
Nominal voltage	3.6 V
Nominal capacity	1.5 Ah
Nominal current	1.3 mA
Max. continuous discharge current	75 mA
Pulse current capability	150 mA
Anode surface area	9 cm <sup>2</sup>
Lithium content	0.5 g
Weight	12.5 g
Volume	5.7 cm <sup>3</sup>
Temperature range	-55 °C ... +85 °C

**WARNING:**  
 Fire, explosion, and severe burn hazard. Do not recharge, disassemble, heat above 100 °C, incinerate, or expose contents to water.


UL recognition under file MH 12827

See also our website under Products/Safety


**Typical Discharge Curves at +25 °C**

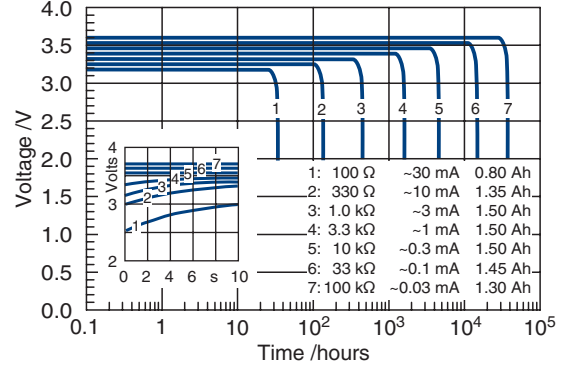



**Available Capacity**

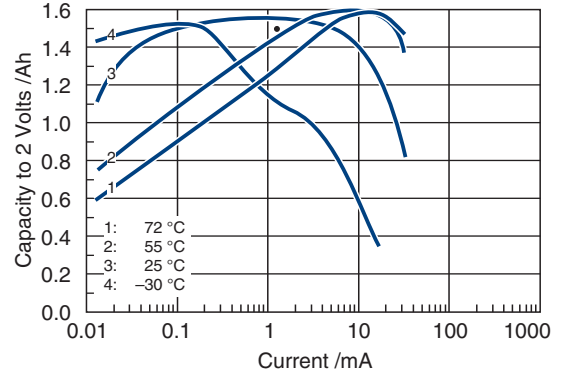

**Operating Voltage**

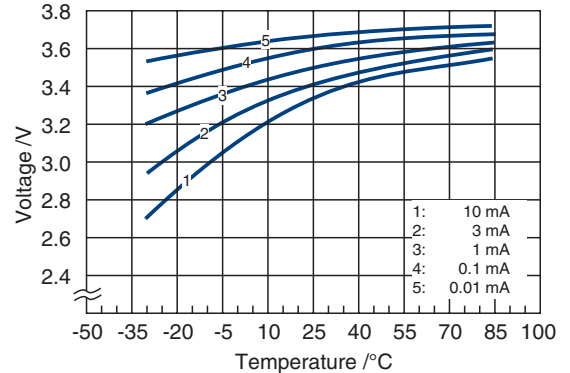

**Voltage Response at +25 °C, pulse: 15 mA**

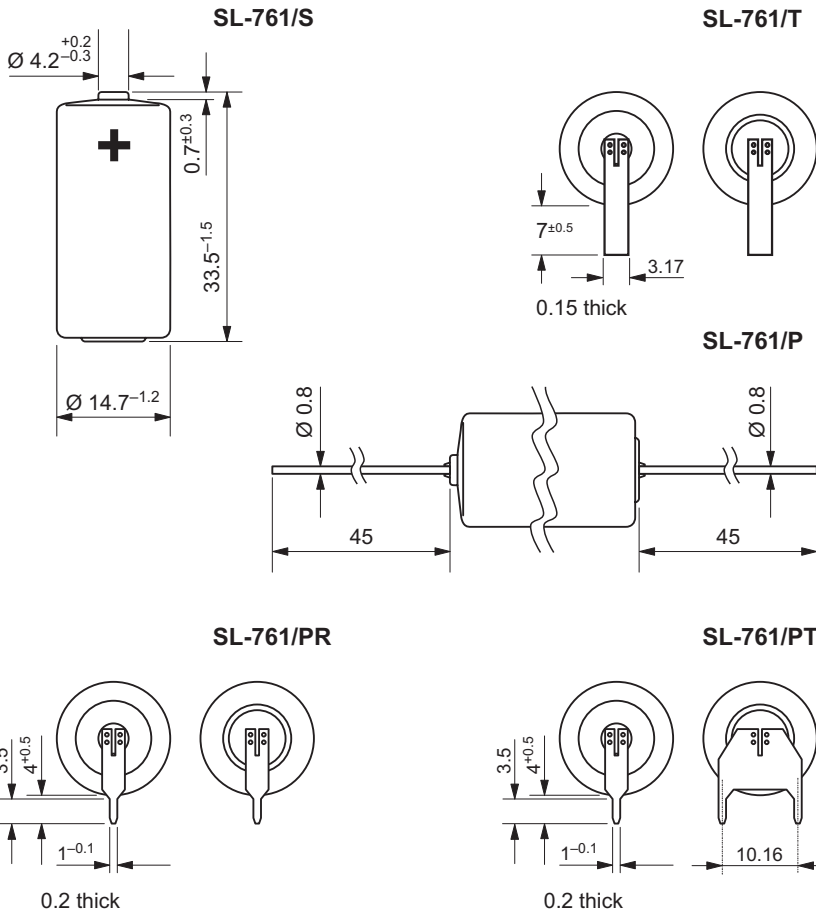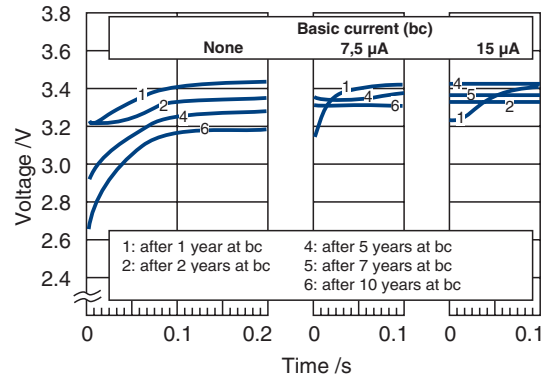

**Available Terminations**

SL-761/S	Standard
SL-761/T	Tags
SL-761/P	Pins
SL-761/PR	Pins Radial
SL-761/PT	Polarized Tags

**Catalogue No.**

11 1 07611 00
11 1 07612 00
11 1 07613 00
11 1 07616 00
11 1 07618 00

Any values given here are for information purposes only. They also depend on actual conditions of use and are not warranties of future performance. Subject to change.