


Plug SLS205-L...


In-line, Ø 2 mm with spring-loaded MULTILAM for self-assembly of test leads.

Solder connection.

SLS205-L

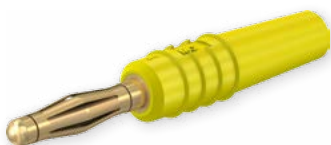

SLS205-L/N

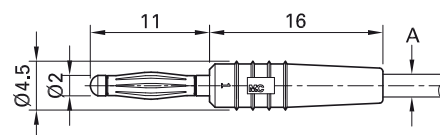

Order No.	Type	Rated voltage/current	Cable (A)			*Colors
22.2618-*	SLS205-L	30 VAC / 10 A 60 VDC / 10 A	max. Ø 2.1 mm	0.5 mm ²	Au	21 22 23 24 25 26 27 28 29
22.2619-*	SLS205-L/N	30 VAC / 10 A 60 VDC / 10 A	max. Ø 2.1 mm	0.5 mm ²	Ni	21 22 23 24 25 26 27 28 29

Component parts

22.2010-*	KT2-S	Insulator
22.1009	LS205-L	Plug for SLS205-L
22.5029	LS205-L/N	Plug for SLS205-L/N



Assembly instructions MA136


www.staubli.com/electrical

Socket SLS205-B

Ø 2 mm rigid for self-assembly of test leads.

Soft insulator.

Solder connection.

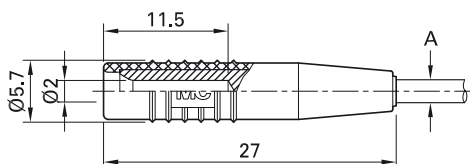

Assembly instructions MA138

www.staubli.com/electrical

Order No.	Type	Rated voltage/current	Cable (A)			*Colors
22.2621-*	SLS205-B	30 VAC / 10 A 60 VDC / 10 A	max. Ø 2.3 mm	0.5 mm ²	Au	21 22 23

Component parts

22.2360-*	KT205-S	Insulator
22.1038	LS205-B	Socket