

Features



- Clear set
- Easy to handle
- 44 values per set
- E12 from 1 pF to 100 nF,
incl. 150nF and 220nF
- Rectangular ceramic capacitor

Variants

SMD-CM-10	10 capacitors per value
SMD-CM-25	25 capacitors per value
SMD-CM-50	50 capacitors per value
SMD-CM-100	100 capacitors per value

Electrical specifications

Dimensions (L x W)	0402 (in inch), 1608 (in mm)
Tolerance	NPO 5%; X7R 10%
Maximum voltage	50, 25, 16, 10 VDC

Values in the sets

NPO				X7R/2R1				
1.0 pF	6.8 pF	47 pF	220 pF		560 pF	1.5 nF	3.9 nF	10 nF
1.5 pF	10 pF	68 pF	270 pF		680 pF	1.8 nF	4.7 nF	12 nF
2.2 pF	15 pF	100 pF	330 pF		820 pF	2.2 nF	5.6 nF	15 nF
3.3 pF	22 pF	150 pF	390 pF		1.0 nF	2.7 nF	6.8 nF	18 nF
4.7 pF	33 pF	180 pF	470 pF		1.2 nF	3.3 nF	8.2 nF	22 nF
								220 nF


Tolerance:

+/- 5% (<10 pF +/- 0.25pF)	+/- 10%
----------------------------	---------

Maximum voltage:


50 V	25 V	16 V		50 V	25 V	16 V	10 V	
------	------	------	--	------	------	------	------	--

Dimensions of the capacitor

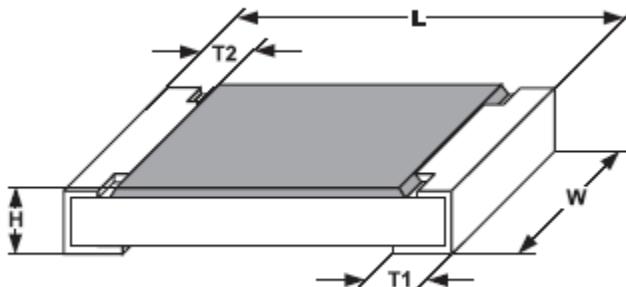

Dimensions [in mm]				
L	W	H	T1	T2
1.0 + 0.05 - 0.05	0.5 + 0.05 - 0.05	0.35 + 0.05 - 0.05	0.25 + 0.05 - 0.05	0.2 + 0.1 - 0.1

 Dimensions of the pads



Dimensions [in mm]					
Reflow			Wave		
a	b	l	a	b	l
0.4	0.6	0.5			

Constructiva AG

Schindellegistrasse 14, 8808 Pfäffikon, Switzerland

Phone +41 55 420 18 65, Fax +41 55 420 18 66

www.constructiva.ch

office@constructiva.ch