



### Features

- Clear set
- Easy to handle
- 60 values per set
- E12 from 10  $\Omega$  up to 1M including 0  $\Omega$ , excluding 12  $\Omega$  and 820 K
- Standard rectangular thick film chip resistors produced by Vishay and Yageo

### Variants

SMD-RCS 25	25 resistors per value
SMD-RCS 50	50 resistors per value
SMD-RCS 100	100 resistors per value


### Electrical specifications

Dimensions (L x W)	0805 (in inch), 2012 (in mm)
Tolerance	$\pm 1\%$
Temperature coefficient	$\pm 100$ ppm/K
Rated dissipation	0.125 W @ 70°C
Maximum voltage	150 V $\cong$

### Values in the sets


0 $\Omega$	33 $\Omega$	100 $\Omega$	330 $\Omega$	1 K	3.3 K	10 K	33 K	100K	330K
10 $\Omega$	39 $\Omega$	120 $\Omega$	390 $\Omega$	1.2 K	3.9 K	12 K	39 K	120K	390K
15 $\Omega$	47 $\Omega$	150 $\Omega$	470 $\Omega$	1.5 K	4.7 K	15 K	47 K	150K	470K
18 $\Omega$	56 $\Omega$	180 $\Omega$	560 $\Omega$	1.8 K	5.6 K	18 K	56 K	180K	560K
22 $\Omega$	68 $\Omega$	220 $\Omega$	680 $\Omega$	2.2 K	6.8 K	22 K	68 K	220K	680K
27 $\Omega$	82 $\Omega$	270 $\Omega$	820 $\Omega$	2.7 K	8.2 K	27 K	82 K	270K	1M

**Dimensions of the resistor**

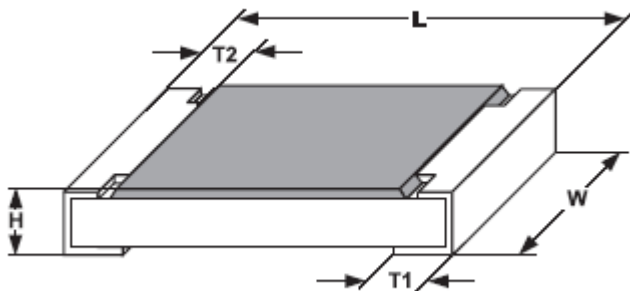

Dimensions [ in mm ]				
L	W	H	T1	T2
2.0	1.25	0.45	0.3	0.3
+ 0.20	+ 0.15	+ 0.05	+ 0.2	+ 0.2
- 0.10	- 0.15	- 0.05	- 0.1	- 0.2

**Dimensions of the pads**

 

Dimensions [ in mm ]					
Reflow			Wave		
a	b	l	a	b	l
0.7	1.3	1.2	0.9	1.3	1.3

**Constructiva AG**  
 Schindellegistrasse 14, 8808 Pfäffikon, Switzerland  
 Phone +41 55 420 18 65, Fax +41 55 420 18 66  
[www.constructiva.ch](http://www.constructiva.ch)  
[office@constructiva.ch](mailto:office@constructiva.ch)