



Portable SSDs



Solid State Drives

Bolt B80




Dimension	75.0 x 75.0 x 11.9mm
Weight	53g
Interface	USB3.1 Gen 2
Cable	Type-C (B80) to Type-A (PC/NB)
Drop test	MIL-STD-810G 516.7 procedure IV
Water/dust proof	IP68
Warranty	3 years



Bolt B10

Dimension	80.0 x 49.5 x 9.4mm
Weight	25g
Interface	USB3.1 Gen 1 (USB 3.0)
Cable	Micro-B (B10) to Type-A (PC/NB)
Warranty	3 years

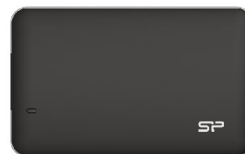

120GB SP120GBPSDB80SCS **480GB** SP480GBPSDB80SCS
240GB SP240GBPSDB80SCS

- Unique shape and sophisticated design
- Robust aluminum casing for high durability
- Extremely compact and lightweight for easy transport and storage
- Uses the new USB Type-C connector
- Superfast with USB 3.1 Gen 2 interface
- LED indicator shows connection and transfer status
- Premium nylon braided cable with SR-enforced (strain relief) connections melded to tough aluminum casings

128GB SP128GBPSDB10SBK **512GB** SP512GBPSDB10SBK
256GB SP256GBPSDB10SBK

- Ultra-compact and lightweight for great portability
- Clean and smooth exterior design
- Large storage capacity of up to 512GB
- Supports LDPC error correction and Wear Leveling

**Note: Performance result may vary, depending on system platform, software, interface and capacity. Please go to our website for more detailed information.

2.5" SATA III Solid State Drives Slim Series

Slim S85



Dimension	100.0 x 69.9 x 7.0mm
Weight (max.)	63g
Flash type	MLC
Vibration	20G
Shock	1500G Max
Power requirement	5V
Transfer speed	Up to R/W 560/540MB/s (ATTO)
Warranty	5 years



480GB SP480GBSS3S85S25
960GB SP960GBSS3S85S25

- 7mm slim design suitable for ultrabooks and ultra-slim laptops
- SATA III 6Gbps backwards compatible with SATA II 3GB/s
- Supports TRIM command and Garbage Collection technology
- NCQ and RAID ready
- ECC technology to guarantee data transmission reliability
- Built-in with SMART monitoring system
- Low power consumption, shock- and vibration-proof, noiseless and low latency

**Note: Performance result may vary, depending on system platform, software, interface and capacity. Please go to our website for more detailed information.

Slim S70



Dimension	100.0 x 69.9 x 7.0mm
Weight (max.)	63g
Flash type	MLC
Vibration	20G
Shock	1500G Max
Power requirement	5V
Transfer speed	Up to R/W 560/500MB/s (ATTO)
Warranty	5 years



120GB SP120GBSS3S70S25 **480GB** SP480GBSS3S70S25
240GB SP240GBSS3S70S25