

Product datasheet

Specifications



pilot light Ø12 - IP40/IP65 - green - covered LED included - 24V - lugs

Local distributor code:

22491215

XVLA333

EAN Code: 3389110651669

Main

Range Of Product	Harmony XVL
Product Or Component Typee	LED pilot light with integral lens cap
Component Name	XVL
Mounting Diameter	12 mm
Light Source	Covered LED
Light Block Colour	Green
Protection Type	Integral ballast resistor Built-in by diode
[Us] Rated Supply Voltage	24 V
Ip Degree Of Protection	IP65 (with seal XVLZ912) conforming to IEC 60529 IP65 (with seal XVLZ912) conforming to NF C 20-010 IP40 conforming to IEC 60529 IP40 conforming to NF C 20-010

Complementary

Supply Circuit Type	DC
Connections - Terminals	Threaded connector: clamping capacity 1 x 0.2...1 x 1.5 mm ²
Current Consumption	18 mA
[Ui] Rated Insulation Voltage	50 V conforming to IEC 60947-1
Bulb Lifespan	100000 h
Nominal Voltage Limit	0.8...1.1 Un
Terminals Description Iso N°1	(X1-X2)PL
Height	16 mm
Width	16 mm
Depth	51 mm
Net Weight	0.007 kg

Environment

Product Certifications	CSA UL
Protective Treatment	TC
Ambient Air Temperature For Operation	-25...70 °C
Ambient Air Temperature For Storage	-40...70 °C

Overvoltage Category	Class 3 conforming to IEC 60536 Class 3 conforming to NF C 20-030
-----------------------------	--

Packing Units

Unit Type Of Package 1	PCE
-------------------------------	-----

Number Of Units In Package 1	1
-------------------------------------	---

Package 1 Height	1.6 cm
-------------------------	--------

Package 1 Width	1.6 cm
------------------------	--------

Package 1 Length	4.9 cm
-------------------------	--------

Package 1 Weight	7.0 g
-------------------------	-------

Unit Type Of Package 2	BB1
-------------------------------	-----

Number Of Units In Package 2	10
-------------------------------------	----

Package 2 Height	3.0 cm
-------------------------	--------

Package 2 Width	9.0 cm
------------------------	--------

Package 2 Length	16.0 cm
-------------------------	---------

Package 2 Weight	73.0 g
-------------------------	--------

Unit Type Of Package 3	S01
-------------------------------	-----

Number Of Units In Package 3	100
-------------------------------------	-----

Package 3 Height	15.0 cm
-------------------------	---------

Package 3 Width	15.0 cm
------------------------	---------

Package 3 Length	40.0 cm
-------------------------	---------

Package 3 Weight	951.0 g
-------------------------	---------

Contractual warranty

Warranty	18 months
-----------------	-----------

Sustainability

Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



Transparency RoHS/REACH

Well-being performance

Mercury Free

Rohs Exemption Information Yes

Certifications & Standards

Reach Regulation [REACH Declaration](#)

Eu Rohs Directive Pro-active compliance (Product out of EU RoHS legal scope)

China Rohs Regulation [China RoHS declaration](#)


Environmental Disclosure [Product Environmental Profile](#)

Weee The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins

Circularity Profile No need of specific recycling operations

LED Pilot Light

Dimensions

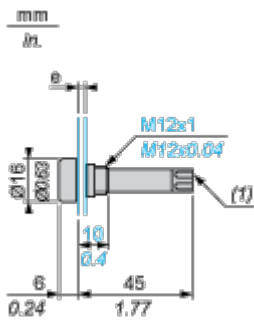


(1) Threaded connector

e panel thickness: 1 to 8 mm/0.03 to 0.31 in.

LED Pilot Light

Panel Drilling

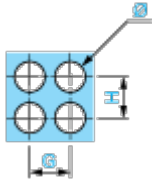

Ø min		G min		H min	
mm	in.	mm	in.	mm	in.
12.2	0.48	16.5	0.65	16.5	0.65