

Power supplies – for CompactPCI and VME64x

AC/DC, 19", 6 U, QUAD


- Wide input voltage range 90 ... 264 V_{AC} with power factor correction (PFC)
- 4 output voltages
- Connector P 47
- Redundant operation with Current Share Bus (CSB), hot-swap
- CompactPCI signalling


DELIVERY COMPRISES

Qty	Description
1	19" compatible power supply height 6 U width A: 8 HP depth 171.93 mm (160 mm board depth) connector P 47 front panel with handles and textile EMC gasket fitted


11308007

ORDER INFORMATION

Voltage V	Current A	Power W	Description	Part no.
V1: 5 V2: 3.3 V3: 12 V4: -12	I1: 50 I2: 60 I3: 12 I4: 4	500	CPCI 500 AC	13100-145
Power backplane with P47 connector 6 U, width 39.6 mm, 1 x connector position P47, top, 1 piece				23098-116
Guide rail with keying/coding, groove width 2.0 mm, with 0.1" offset , Standard pack quantity 50 pieces				64560-071

Note

- Output data at T_A = -25 ... 55 °C with forced air cooling of 1.5 m/s
- 47-pin CompactPCI connector to PICMG 2.11 specification

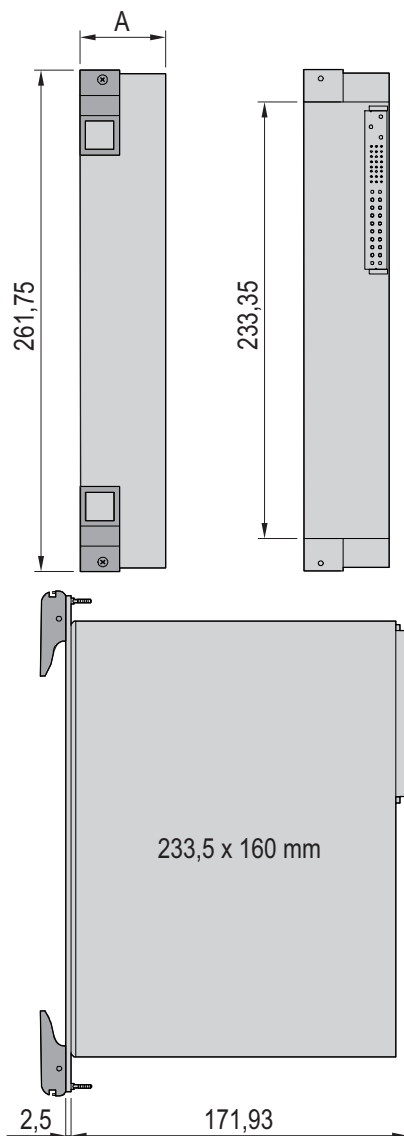

11302051