

SILVER STORM™ WIRELESS MEDICAL MOUSE - AES128 ENCRYPTION

Model: STM042WE, STWM042WE

Seal Shield Silver Storm™ Wireless Medical-Grade Mouse has a 100% waterproof & dishwasher-safe rating that is IP68-certified (highest rating), and is compatible with medical-grade cleaners & disinfectants. Specialized design stands up to vigorous and regular cleaning while enabling the elimination of debris and harmful pathogens in hard-to-reach crevices. Features convenient wireless connection & includes a charging base with 3 universal USB ports (charging base is not waterproof).

FEATURES:



100% Waterproof & Dishwasher Safe



Compatible with Hospital Cleaners & Disinfectants



Wireless Connection & charging base with 3 Universal USB Ports



Battery Charge Indicator Light



IP 68 Certified (highest waterproof rating)




STWM042WE (White)



STM042WE

MEDICAL-GRADE CLEANING CAPABILITIES

- Dishwasher-Safe (Hot & Cold settings)
- Bleach compatible. Clorox® approved. (including Clorox HealthCare Products)
- Disinfectants & Sporicides (including Lysol® products EPA-certified to kill COVID-19)
- Solvents, Corrosives and Acids
- Alcohol and H. Peroxide

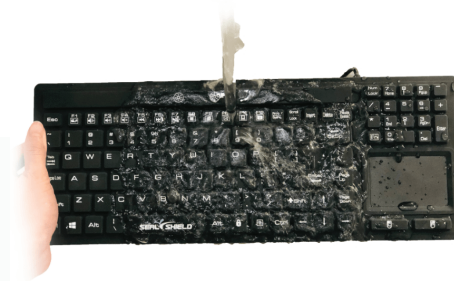

SILVER STORM™ WIRELESS MEDICAL MOUSE - AES128 ENCRYPTION

Model: STM042WE, STWM042WE

TECHNICAL DATA:

| | |
|-------------------------------|--|
| Compatibility: | Window [®] s, Mac [®] (USB Models) |
| Construction: | ABS Plastic |
| Design: | 2 Button with Scroll Wheel (clickable) |
| Net Dimension: | 4.6 x 2.35 x 1.43 in (11.7 x 5.96 x 3.62 cm) |
| Base Dimensions: | 3.9 x 4.1 x 3.9 in (10.0 x 10.4 x 10.0 cm) |
| Mouse Weight: | 0.17 lb (80 g) |
| Base Weight: | 0.30 lb (140 g) |
| Base Cable Length: | 6 ft (1.83 m) |
| Connection Type: | 2.4 GHz RF Wireless (Dongle Receiver USB) |
| Button Switch Force: | 100 ± 20 gf |
| Button Switch Life Cycle: | >10 Million Clicks |
| Scroll Type: | Scroll Wheel |
| Resolution: | 1000 DPI |
| Optical Technology: | LED |
| Operating Voltage: | + 5VDC ± 5% |
| Storage Temperature: | 5° - 140° F (-15° to 60° C) |
| EMI - RFI: | Conforms to FCC Rules for Class B Device |
| Waterproof/Dustproof Ratings: | 100% Waterproof & Dustproof (IP68, NEMA 4X) |
| Approvals/Certifications: | FCC, CE, RoHS, WEEE, REACH, RSS-210 |



Copyright© 2020, Seal Shield, LLC. All rights reserved. All other trademarks and trade names are those of their respective owners.

Limited 1-Year Warranty