



AS-Interface distributor compact for AS-i profile cable IP 67/68/69K, max. 8 A

General technical data		
Type of device		AS-Interface accessories
Function		distribution function for AS-i flat cables
operating voltage according to AS-Interface specification	V	26.5 ... 31.6
operational current rated value	A	8
Note		cable must not end in the feeder
Connections/ Terminals		
type of electrical connection		insulation piercing method for AS-Interface flat cable
Mechanical data		
Type of mounting		screw fixing
tightening torque of fixing screw	N·m	1.65 ... 1.65
Contacts Load rating max	A	12
Ambient conditions		
ambient temperature	°C	-25 ... +75
ambient temperature during storage	°C	-25 ... +85
degree of protection		IP67/68/69K
Certificates/ approvals		
General Product Approval	EMV	Marine / Shipping



EG-Konf.

[Confirmation](#)



UL



RCM



PRS


other	Environment
-------	-------------

[Confirmation](#)

[Environmental Confirmations](#)

Further information

- Information on the packaging
<https://support.industry.siemens.com/cs/ww/en/view/109813875>
- Information- and Downloadcenter (Catalogs, Brochures,...)
<https://www.siemens.com/ic10>
- Industry Mall (Online ordering system)
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3RK1901-2NN10>
- Cax online generator
<http://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3RK1901-2NN10>
- Service&Support (Manuals, Certificates, Characteristics, FAQs,...)
<https://support.industry.siemens.com/cs/ww/en/ps/3RK1901-2NN10>

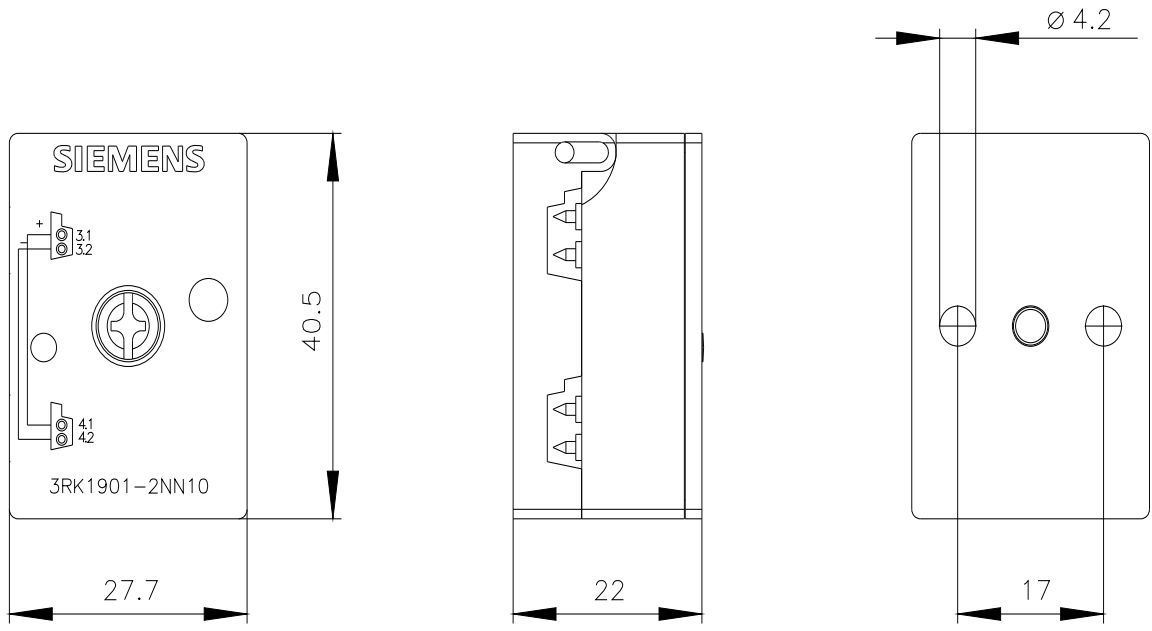

last modified:

12/23/2020 