


SODIMM

 silicon-power.com/web/gb/product-DDR4_SODIMM_Industrial

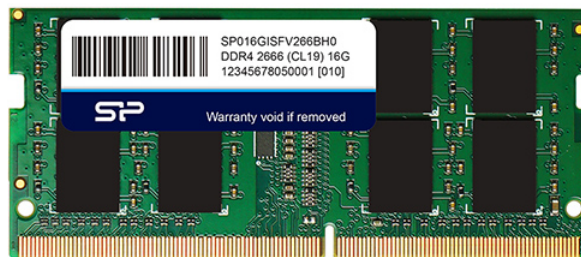

Specifications

- Capacity
 - 2GB, 4GB, 8GB, 16GB, 32GB
- Voltage
 - 1.2V
- Storage Temperature
 - -55°C ~ 95°C
- CAS Latency
 - CL17 / CL19 / CL22
- Data Rate
 - 2400 / 2666 / 3200*MHz
- Pin Count
 - 260pin

- Data Width
- 64Bits
- PCB Height
- 1.18" (30.13mm)
- Operating Temp. (Standard)
- SP***GISFU*****
- Operating Temp. (Wide)
- SP***GISFV*****
- Operating Humidity
- 10% ~ 95% (30°C Max. Wet Bulb Temp)
- Warranty
- 10 years

Features

- High performance transfer bandwidth reaches up to 19.2GB/s ~ 25.6GB/s
- Low voltage of 1.2V for less power consumption
- Original and high quality memory module
- 100% tested for stability, durability, and compatibility
- 30 micro inches Gold Finger Plating (optional)
- Supports operating temperatures from -40°C – 85°C
- Wide Temperature version available by request
- 3200MHz is only available at 8GB ,16GB, 32GB

DDR4 SODIMM

Description	DIMM Type	Capacity	Frequency	CAS Latency	Configuration	RANK(S)	Temp.	P/N
DDR4	SO-DIMM	2GB	2666	CL19	256Mx16	SR	0~85°C	SP002GISFU266WN0
DDR4	SO-DIMM	4GB	2666	CL19	512Mx8	SR	0~85°C	SP004GISFU266NS0
DDR4	SO-DIMM	4GB	2666	CL19	512Mx16	SR	0~85°C	SP004GISFU266CH0
DDR4	SO-DIMM	4GB	2400	CL17	512Mx8	SR	0~85°C	SP004GISFU240NH0
DDR4	SO-DIMM	4GB	2666	CL19	512Mx8	SR	0~85°C	SP004GISFU266NH0
DDR4	SO-DIMM	4GB	2400	CL17	512Mx8	SR	-40~85C	SP004GISFV240NH0
DDR4	SO-DIMM	4GB	2666	CL19	512Mx8	SR	-40~85C	SP004GISFV266NH0
DDR4	SO-DIMM	8GB	2666	CL19	1Gx8	SR	0~85°C	SP008GISFU266BS0
DDR4	SO-DIMM	8GB	2400	CL17	512Mx8	DR	0~85°C	SP008GISFU240NH0
DDR4	SO-DIMM	8GB	2666	CL19	512Mx8	DR	0~85°C	SP008GISFU266NH0
DDR4	SO-DIMM	8GB	2666	CL19	1Gx8	SR	0~85°C	SP008GISFU266BH0

DDR4	SO-DIMM	8GB	3200	CL22	1Gx8	SR	0~85°C	SP008GISFU320BH0
DDR4	SO-DIMM	8GB	2666	CL19	1Gx8	SR	-40~85C	SP008GISFV266BH0
DDR4	SO-DIMM	16GB	2666	CL19	1Gx8	DR	0~85°C	SP016GISFU266BS0
DDR4	SO-DIMM	16GB	2666	CL19	1Gx8	DR	0~85°C	SP016GISFU266BH0
DDR4	SO-DIMM	16GB	3200	CL22	1Gx8	DR	0~85°C	SP016GISFU320BH0
DDR4	SO-DIMM	16GB	2666	CL19	1Gx8	DR	-40~85C	SP016GISFV266BH0
DDR4	SO-DIMM	32GB	2666	CL19	2Gx8	DR	0~85°C	SP032GISFU266FS0