

Ø 4 mm connecting plugs

Test & Measureline | Test & Measurement

EN



Ø 4 MM SYSTEM


Connecting plug

Connecting plug K...4N-19


Insulated, Ø 4 mm, made of brass. Plugs with spring-loaded MULTILAM contact technology. With insulated grip. At rear with-

out or with two in-line Ø 4 mm rigid sockets accepting spring-loaded Ø 4 mm plugs.

KS-4N-19

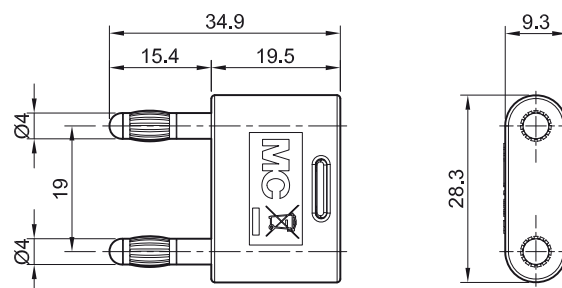

KS2-4N-19

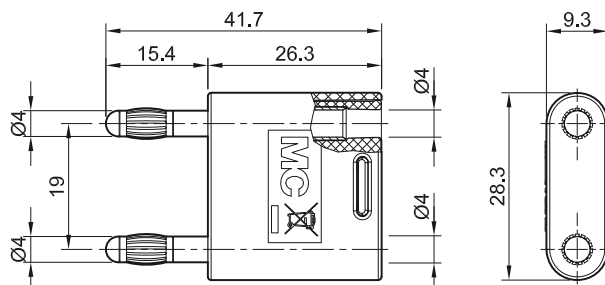

Order No.	Type	Rated voltage/current	Plug spacing		*Standard colors															
64.4012-*	KS-4N-19	AC 30 V/32 A DC 60 V/32 A	19 mm	Ni	<table border="1"> <tr> <td>20</td><td>21</td><td>22</td><td>23</td><td>24</td> </tr> <tr> <td>25</td><td>26</td><td>27</td><td>28</td><td>29</td> </tr> <tr> <td>30</td><td></td><td></td><td></td><td></td> </tr> </table>	20	21	22	23	24	25	26	27	28	29	30				
20	21	22	23	24																
25	26	27	28	29																
30																				
64.4010-*	KS2-4N-19	AC 30 V/32 A DC 60 V/32 A	19 mm	Ni	<table border="1"> <tr> <td>20</td><td>21</td><td>22</td><td>23</td><td>24</td> </tr> <tr> <td>25</td><td>26</td><td>27</td><td>28</td><td>29</td> </tr> <tr> <td>30</td><td></td><td></td><td></td><td></td> </tr> </table>	20	21	22	23	24	25	26	27	28	29	30				
20	21	22	23	24																
25	26	27	28	29																
30																				



User information **i099**


www.staubli.com/electrical

Connecting plug SK...4N-19


Insulated, Ø 4 mm, made of brass. Plugs with spring-loaded MULTILAM contact technology and rigid insulating sleeves. With insulated grip. At rear without or with

in-line Ø 4 mm rigid sockets accepting spring-loaded Ø 4 mm plugs with rigid insulating sleeve.

SKS-4N-19

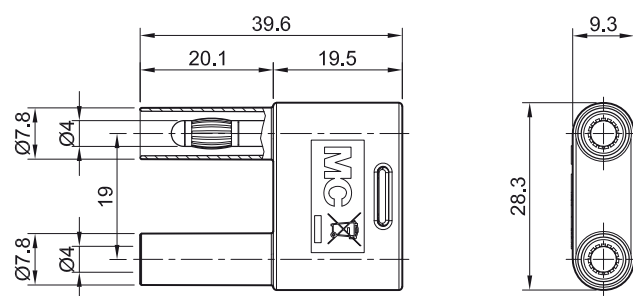

SKS2-4N-19

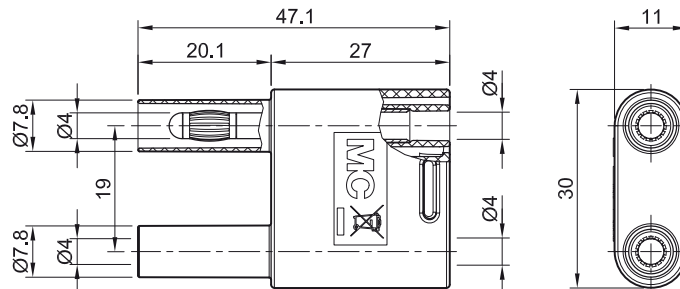

Order No.	Type	Rated voltage/current	Plug spacing		*Standard colors															
66.4012-*	SKS-4N-19	1000 V, CAT II/32 A	19 mm	Ni CE c UL us	<table border="1"> <tr> <td>20</td> <td>21</td> <td>22</td> <td>23</td> <td>24</td> </tr> <tr> <td>25</td> <td>26</td> <td>27</td> <td>28</td> <td>29</td> </tr> <tr> <td>30</td> <td></td> <td></td> <td></td> <td></td> </tr> </table>	20	21	22	23	24	25	26	27	28	29	30				
20	21	22	23	24																
25	26	27	28	29																
30																				
66.4010-*	SKS2-4N-19	1000 V, CAT II/32 A	19 mm	Ni CE c UL us	<table border="1"> <tr> <td>20</td> <td>21</td> <td>22</td> <td>23</td> <td>24</td> </tr> <tr> <td>25</td> <td>26</td> <td>27</td> <td>28</td> <td>29</td> </tr> <tr> <td>30</td> <td></td> <td></td> <td></td> <td></td> </tr> </table>	20	21	22	23	24	25	26	27	28	29	30				
20	21	22	23	24																
25	26	27	28	29																
30																				



● Stäubli Units ○ Representatives/Agents

Global presence of the Stäubli Group

www.staubli.com