

**NEW!**

Available September, 2017

## BHG 360 Li-Ion

100 % more run time at 0% price increase!

- The new battery with a higher capacity and newest battery technology allows a heavily increased running time
- NEW: 4,0 ampere hours (before 2,6 ampere hours)
- New running time: Up to 30 min.!




# BHG 360 Li-Ion

100 % more run time at 0% price increase!

100%  
more  
run time

Technical data

Power: 300 W  
 Temperature: 500° C with reducing nozzle (included), 400° C without nozzle  
 Air volume: 100 l/min  
 Stages: Cold and hot air stage  
 Specials: Up to 30 Minuten battery run time, integrated LED working light, hanger, different nozzles included, soft grip ergonomically designed  
 Scope of delivery: Functional case and different nozzles included: Reducing nozzle 7 mm, reducing nozzle with protection reflector, precision reflector nozzle, reflector nozzle 10 mm and reflector nozzle 40 mm

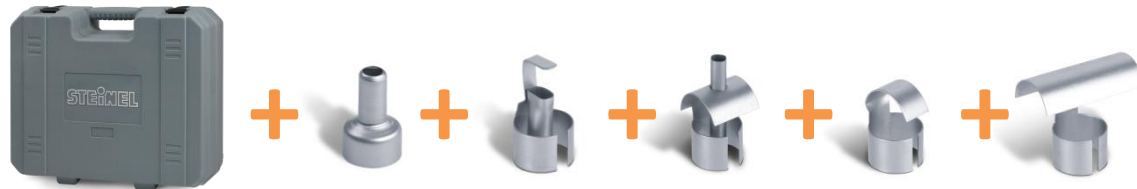

EAN-Code	Art.-No.	Bezeichnung Description	VE min.order qty.	Exportpreis / St. Export price / pc.	Europapreis / St. European price / pc.	UVP zzgl. MwSt / St. rec.sales price / pc.
4007841 351052	351052	Battery hot air tool BHG 360 Li-Ion	1			
4007841 004101	004101	Spare part battery 36 volt Li-Ion	1			