


8-Port Cat. 5e Unshielded Patch Panel TC-P08C5E (v2.0R)

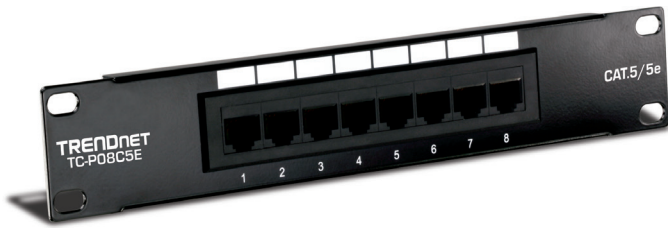

The 8-Port Cat. 5e Unshielded Patch Panel, provides a 100 MHz connection to 8 x Gigabit RJ-45 Ethernet ports. This 10 inch wide patch panel is well suited for home and SMB applications. Control cable clutter with included removable cable pass-through holders and cable ties. A writing surface above each port allows users to label respective connections. Use with TRENDnet's Punch Down Tool with 110 and Krone Blade, model TC-PDT, and RJ-11/RJ-45 crimp/cut/strip tool, model TC-CT68.

PRODUCT OVERVIEW

- 8 x Gigabit RJ-45 ports
- 10 inch wide patch panel is well suited for home and SMB applications
- Designed for Category 5e cabling
- Includes cable management holders, tie, and port labels
- Use with TRENDnet TC-PDT Punch Down Tool

FEATURES

- 8 x 1000Base-T Gigabit RJ-45 ports
- Supports a 100 MHz connection
- 10 inch wide patch panel
- Cat. 5e color coded labeling for T568A and T568B wiring schemes
- IDC terminal blocks are compatible with 110 and Krone style connectors
- Labels above each port
- Cat. 5e transmission performance compliant with ANSI, TIA, and EIA 568 B.2 standards
- Nylon cable ties and holders included
- 3-year limited warranty

8-Port Cat. 5e Unshielded Patch Panel

TC-P08C5E (v1.0R)



SPECIFICATIONS

HARDWARE

Wiring standards	• T568A and T568B
Network Media	• Cat. 5e
Mounting Point Retention Strength	• 7.7 kg (17 lb.)
Dimension (L x W x H)	• 254 x 44 x 30 mm (10 x 1.7 x 1.2 in.)
Weight	• 205 g (7.2 oz)
Temperature	• -10 - 60°C (14 - 140°F)
Certifications	• CE, FCC

PACKAGE CONTENTS

TC-P08C5E

Quick Installation Guide

Cable holders and ties

RELATED PRODUCTS

TC-P12C5E	12-Port Cat. 5e Unshielded Patch Panel
TC-P24C5E	24-port Cat5/5e Unshielded Patch Panel
TC-PDT	Replacement Blade for TC-PDT

CONTACT INFORMATION

TRENDnet

20675 Manhattan Place, Torrance, CA 90501 USA

Tel: 1-310-961-5500

Fax: 1-310-961-5511

Web: www.trendnet.com

Email: sales@trendnet.com

1-888-326-6061

